

Display Port Adapters

Mini Display Port Adapters

Part No: 2409EMV

The mini DisplayPort 1.1a compliant adaptors and cables are designed to be used to connect equipment that feature the mini DisplayPort connector. They support high definition video as well as multi channel digital audio.



Specification


Input	Output
● Mini DisplayPort M	VGA F
● Max 1920x1200	Max 1920x1200
Operating Frequency	
● Vertical Frequency Range	50/60Hz 162MHz
● Bandwidth	225MHz/2.25Gbps / channel
Physical	
● Size (LxWxD)	45 x 45 x 15mm
● Weight (Net)	30g
● Colour	White
● Conector	Nickel Plated
Operational	
● Operating Temp.	0°C to +55°C
● Operating Humidity	10% to 85% RH (no condensation)
● Storage Temp.	0°C to +70°C
● Storage Humidity	5% to 90% RH (no condensation)
● Power Requirement	No external power needed
● Regulatory Approvals	CE, FCC, RoHS

Features & Benefits

- Supports pure digital direct HD video and audio from source
- High performance cables featuring Mini DisplayPort connection
- Designed to improve digital display connectivity

Display Port Adapters Mini Display Port Adapters

Part No: 2409EMV

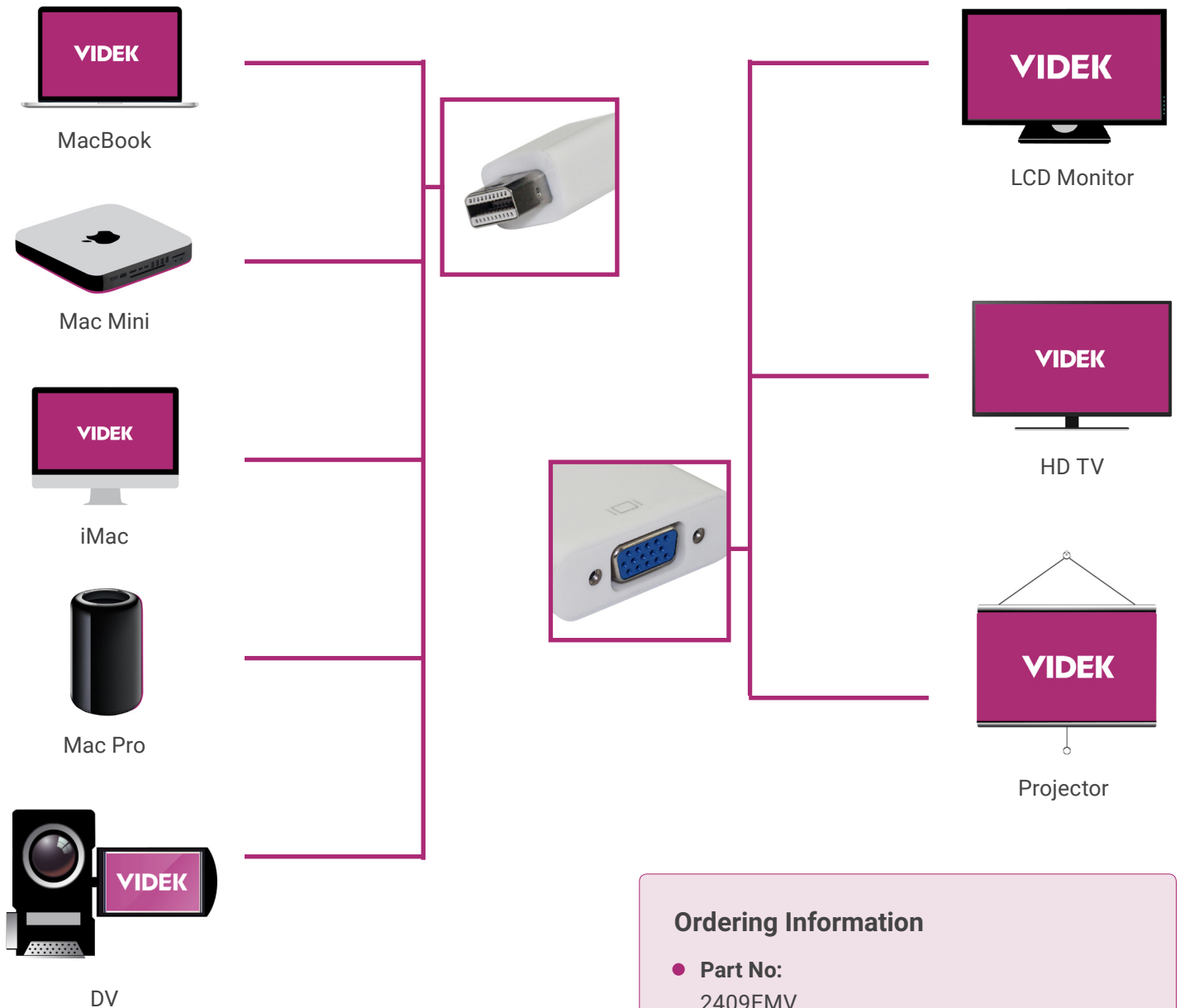

Ordering Information

- **Part No:**
2409EMV
- **Product Description:**
VIDEK Mini Display Port Plug to VGA Socket Adaptor - White