

Energizer® Expert LED Lantern

GRD1LB6

Featuring two powerful spot light modes plus a broad area light mode, the *Energizer*® Expert LED Lantern projects up to 500 meters, making it an ideal light for a wide range of industrial applications. The head pivots 140° and allows users to direct the light precisely where needed. It is easy to operate, with a push button switch and a detachable carrying strap. With energy-efficient LED technology and multiple beam distance settings, the Expert LED Lantern combines an extraordinary brightness and long lasting runtime that can be optimized for a variety of needs.




Provides 500 Lumens of Light



Provides Run Time of 40 hours



Sustains 1 Meter Drop Test.

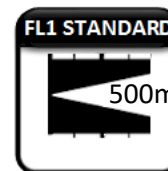

Illuminates objects up to 500 meters away.

DESIGN BENEFITS

- ✓ Rugged, alloy construction
- ✓ Designed to Last up to 15 years
- ✓ Head swivels 140° to direct light where you need it
- ✓ Easy-to-use push button switch
- ✓ Shatterproof lens

LIGHT AND POWER SOURCE

- ✓ Features LED Technology
- ✓ Operates on 6V Battery included

CERTIFICATES AND COMPLIANCE

CE RoHS

EMC, EN62471,



Tested according to ANSI/NEMA FL1 Standards.

Results based on: Energizer, Alkaline 6V / 1014 6V

PERFORMANCE BENEFITS

- ✓ Up to 10X Brighter than standard LED technology
- ✓ Extended run time
- ✓ High intensity beam
- ✓ Three operating modes

SPECIFICATIONS

Weight Excluding Batteries:

689 Grams / 24.3 Ounces

Dimensions:

152mm x 216mm / 6 x 8.5"

NUMBER OF OPERATING MODES: 3

Mode	Lumens (lm)	Runtime (h)
High	500	40
Medium	400	50
Low	150	120