


ENERGIZER HARD CASE PROFESSIONAL® Task Light HCHH212

For the most demanding tasks, look no further than the *Energizer*® *HARDCASE PROFESSIONAL*® Task Light. With tool-quality construction and advanced LED technology, this light is designed to meet even the most demanding jobs. Constructed with professionals in mind, it withstands drop after drop, off a ladder or even a two story building. The large push button switch can be easily operated while wearing gloves, and the newest *Energizer*® Smart Dimming Feature allows a personalized light intensity control ideal for power saving. In addition, this light is water resistant making it perfectly suited for outdoor use.

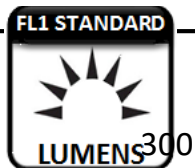


Provides 300 Lumens of Light



Provides Run Time of 6 hours 30 minutes



Sustains 7 Meter Drop Test

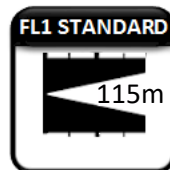

Illuminates objects up to 115 meter away



Water Resistant IPX4 - works after splashing water on all sides

DESIGN BENEFITS

- ✓ 20 Year Design To Last based on typical consumer usage patterns
- ✓ Exceptionally durable construction for the most demanding jobs
- ✓ Survives drop after drop from a two-story building
- ✓ Built -in lanyard slot

LIGHT AND POWER SOURCE

- ✓ Features LED Technology
- ✓ Operates on 2 AA batteries

ELECTRICAL CHARACTERISTICS

Electrical Characteristics Nominal Power:
Power consumption xxxW / Battery Energizer E91 xxxV dc
LED Specifications: LED 3.0V cc / xxx mA

CERTIFICATES AND COMPLIANCE

CE RoHS
EMC, EN62471, FCC



This device complies with part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) This device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Tested according to ANSI/NEMA FL1 Standards

Results based on: Energizer® MAX® Alk / E91

PERFORMANCE BENEFITS

- ✓ *Energizer* Smart Dimming feature controls light intensity for power saving
- ✓ LED technology provides clear, bright light
- ✓ High and low modes for customized brightness and runtime
- ✓ Water resistant for outdoor tasks

SPECIFICATIONS

Weight Excluding Batteries:

100 Grams / 3.5 Ounces

Dimensions:

30mm x 35mm x 165mm / 1.2" x 1.4" x 6.5"

NUMBER OF OPERATING MODES: 2

Mode	Lumens (lm)	Runtime (h)	Beam Distance (m)
High	300	6h 30m	115
Low	45	65	45