


Rubber Flashlight

RBR212

The *Energizer*® Rubber Flashlight features bright LED technology and a durable ergonomic design. This light offers a non-slip, textured rubber handle for ergonomics and enhanced durability. Designed with a convenient, built-in stand, the light provides hands-free use whenever needed. An integrated lanyard loop makes it easy to attach, while the durable push-button switch is designed to last. The *Energizer* Rubber Flashlight is the ultimate do-it-yourself light that provides excellent performance and reliability for all types of projects.




Provides
60
Lumens of
Light

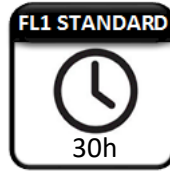

Provides
Run Time
of 30
Hours



Sustains 1
Meter
Drop Test

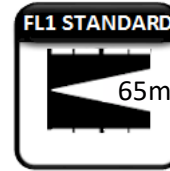

Illuminates
objects up to
65 meters
away

DESIGN BENEFITS

- ✓ Durable rubber construction
- ✓ Non-slip grip
- ✓ Convenient, built-in stand
- ✓ Can be attached to lanyard or carabineer
- ✓ Shatterproof lens

LIGHT AND POWER SOURCE

- ✓ Features LED Technology
- ✓ Operates on 2 AA Batteries

ELECTRICAL CHARACTERISTICS

Electrical Characteristics Nominal Power:
Power consumption 0.45W / Batteries AA
Energizer E91 3.0V dc
LED Specifications: LED 3.0V cc / 150 mA

CERTIFICATES AND COMPLIANCE

CE RoHS
EMC, EN62471



Tested according to ANSI/NEMA FL1 Standards

Results based on: Energizer® MAX® Alkaline / E91

PERFORMANCE BENEFITS

- ✓ Up to 10X Brighter vs. ordinary LED technology
- ✓ Long lasting runtime
- ✓ Excellent beam distance

SPECIFICATIONS

Weight Excluding Batteries:

240 Grams / 8.5 Ounces

Dimensions:

191mm x 62mm x 71mm / 7.5" x 2.4" x 2.8"

NUMBER OF OPERATING MODES: 1

Mode	Lumens (lm)	Runtime (h)	Beam Distance (m)
On	60	30	65