


# Compact Rubber Flashlight

# RBR222

The *Energizer*® Compact Rubber Flashlight features bright LED technology and a durable ergonomic design. This light offers a non-slip, textured rubber handle for ergonomics and enhanced durability. Designed with a convenient, built-in stand, the light provides hands-free use whenever needed. An integrated lanyard loop makes it easy to attach, while the durable push-button switch is designed to last. The *Energizer* Compact Rubber Flashlight is the ultimate do-it-yourself light that provides excellent performance and reliability for all types of projects.

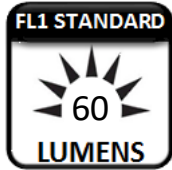


Provides  
60  
Lumens of  
Light



Provides  
Run Time  
of 18  
Hours



Sustains 1  
Meter  
Drop Test

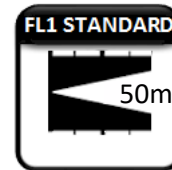

Illuminates  
objects up to  
50 meters  
away

### DESIGN BENEFITS

- ✓ Durable rubber construction
- ✓ Non-slip grip
- ✓ Convenient, built-in stand
- ✓ Can be attached to lanyard or carabiner
- ✓ Shatterproof lens

### LIGHT AND POWER SOURCE

- ✓ Features LED Technology
- ✓ Operates on 2 AAA Batteries

### ELECTRICAL CHARACTERISTICS

Electrical Characteristics Nominal Power:  
Power consumption 0.45W / Batteries AAA  
Energizer E92 3.0V dc  
LED Specifications: LED 3.0V cc / 150 mA

### CERTIFICATES AND COMPLIANCE

CE RoHS  
EMC, EN62471



Tested according to ANSI/NEMA FL1 Standards

Results based on: Energizer® MAX, Alk / E92

### PERFORMANCE BENEFITS

- ✓ Up to 10X Brighter vs. ordinary LED technology
- ✓ Long lasting runtime
- ✓ Excellent beam distance

### SPECIFICATIONS

#### Weight Excluding Batteries:

108 Grams / 3.8 Ounces

#### Dimensions:

149mm x 43mm x 57mm / 5.9" x 1.7" x 2.2"

### NUMBER OF OPERATING MODES: 1

Mode	Lumens (lm)	Runtime (h)	Beam Distance (m)
On	60	18	50

Before using your flashlight, please read all instructions and cautionary marking on the package and the light.

This datasheet contains information specific to products manufactured at the time publication. Contents do not constitute a claim or warranty.

©2018 Energizer