

8-Port 10/100/1000Mbps Desktop Switch

Model: MS108G


// Highlights

- 8 10/100/1000Mbps Auto-Negotiation RJ45 Ports with Auto MDI / MDIX Support
- Half and full Duplex, MAC Address Learning
- 10/100/1000Mbps at Half Duplex, 20/200/2000Mbps at Full Duplex
- Easily wired network expansion
- Compact design for flexible arrangement
- Plug and play setup, no configuration required



// Connections

The MS108G is fully compatible with computers, printers, IP cameras, smart TVs, game consoles and more. Instantly turn your home, small office, and even dormitory into a connected environment.

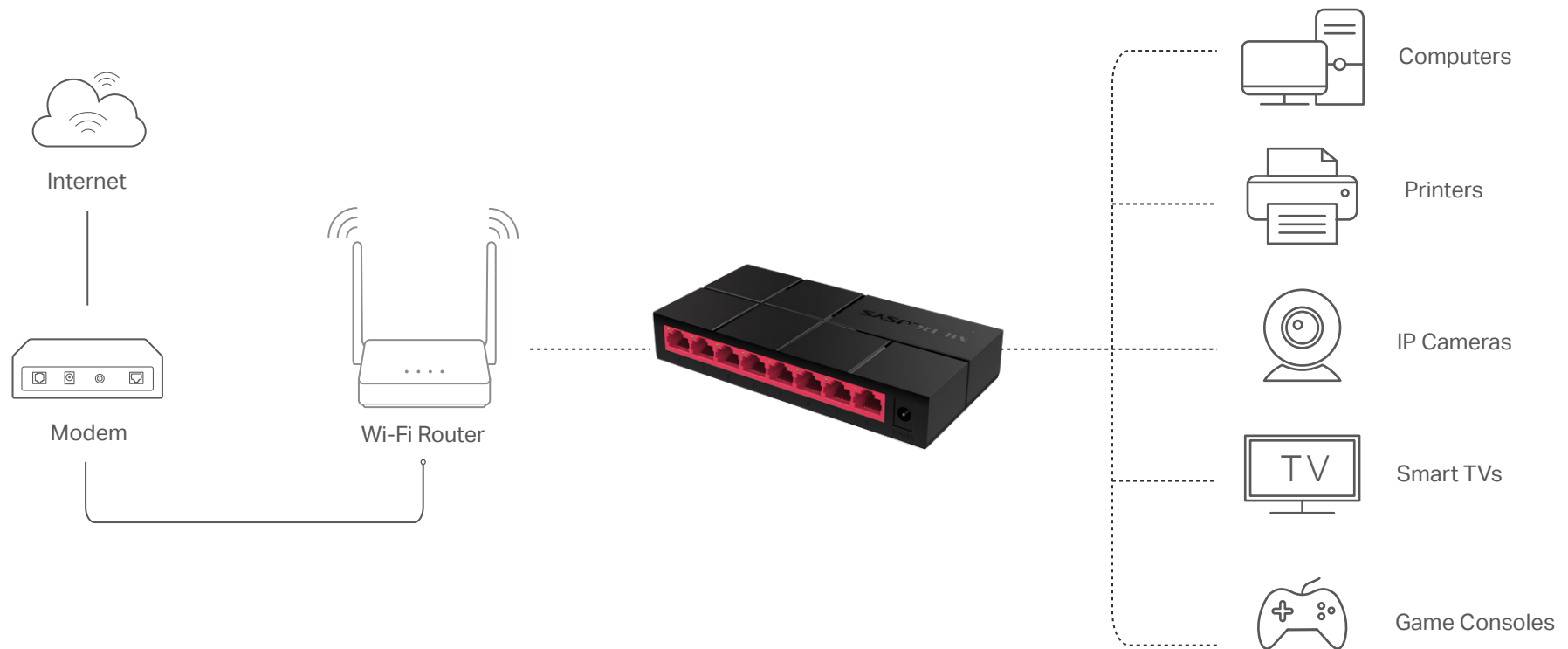

// Specifications

Physical Specifications

Interface	LED	External Power Supply	Dimensions (W x D x H)
8 10/100/1000Mbps Ports, Auto-Negotiation, Auto-MDI/MDIX	Ethernet (1, 2, 3, 4, 5, 6, 7, 8), Power	9V/0.6A	127 x 60.3 x 22mm

Switching Specifications

Standards and Protocols	Data Rates	Buffer Capacity	Jumbo Frame	Transfer Method
IEEE 802.3, IEEE 802.3u, IEEE 802.3x CSMA/CD	10/100/1000Mbps at Half Duplex 20/200/2000Mbps at Full Duplex	64KB	9KB	Store and Forward

// Package Contents

- 8-Port 10/100/1000Mbps Desktop Switch (MS108G)
- Power Adapter
- Quick Installation Guide

For more information, please visit
www.mercusys.com

MERCUSYS TECHNOLOGIES CO., LTD.
3rd Floor, Building R1-B, No. 23, Gaoxin 4th Road, South
Hi-Tech Park, Nanshan, Shenzhen, P.R.China

Specifications are subject to change without notice. MERCUSYS is a registered trademark of MERCUSYS TECHNOLOGIES CO., LTD. Other brands and product names are trademarks or registered trademarks of their respective holders. Copyright © 2019 MERCUSYS TECHNOLOGIES CO., LTD. All rights reserved.