



Main

Range	TeSys
Product or component type	Rotary handle
Device short name	GV7AP
Range compatibility	TeSys GV7 motor circuit breaker
Accessory / separate part category	Control accessory
Rotary handle mounting location	Front
Rotary handle mounting style	Direct

Complementary

Handle colour	Black
Handle front plate colour	Black
Rotary handle padlocking	1 to 3 padlocks 5...8 mm Padlock in OFF position
Net weight	0.205 kg

Environment

IP degree of protection	IP40
-------------------------	------

Offer Sustainability


Sustainable offer status	Green Premium product
RECh Regulation	RECh Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information

Environmental Disclosure	Product Environmental Profile
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

Contractual warranty


Warranty	18 months
----------	-----------

Direct Rotary Handle GV7AP03, GV7AP04

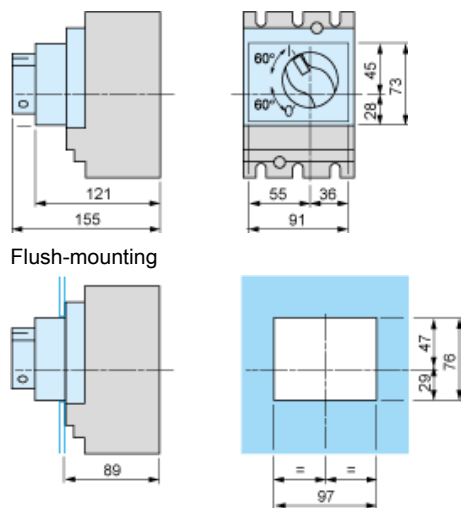


Flush-mounting


Direct Rotary Handle GV7AP03 or GV7AP04 with Conversion Accessory GV7AP05

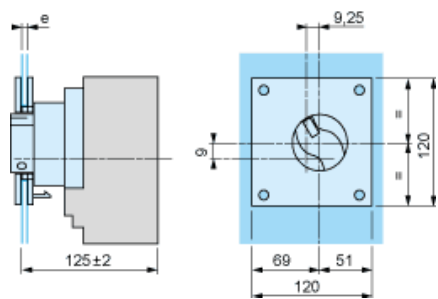

Front face cut-out

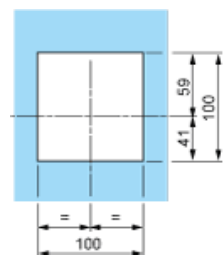

Enclosure viewed from top

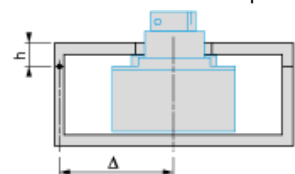

Door cut-outs require a minimum distance between the centre of the circuit breaker and the door hinge point $\Delta \geq 100 + (h \times 5)$

GV7AP03 is replaced by:



Spare parts GV5AP03

Direct rotary handle, TeSys GV5, black, IP40

Qty 1

Reason for Substitution: End of life | Substitution date: 15 April 2019
