


Capacitor, tantalum, 1000 uF, 10% Tol, 4V@85C, E

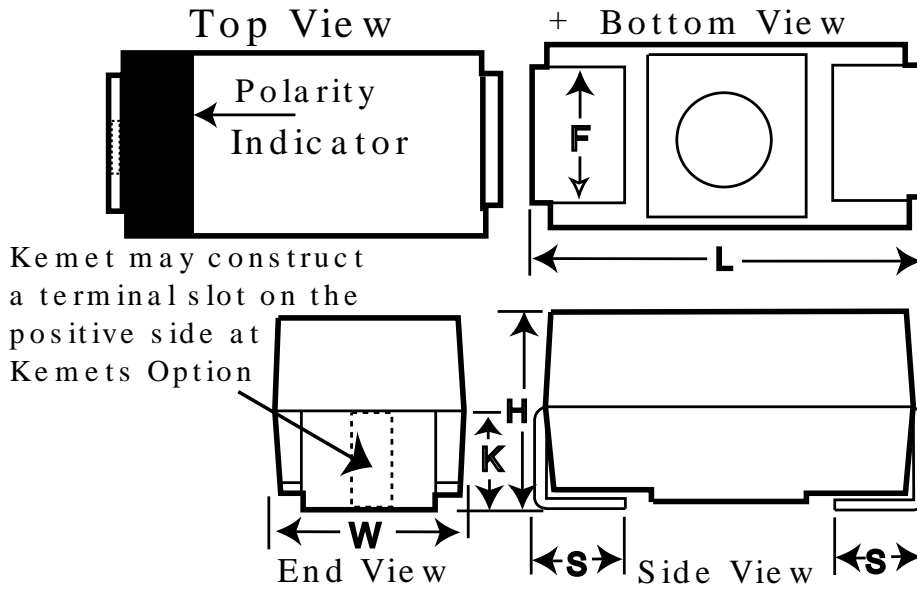

Dimensions (mm)

Specifications

ID	Dimension	Tolerance	Application:	General Purpose
L	7.30	+/-0.30	Capacitance:	1000 uF
W	4.30	+/-0.30	Tolerance:	10%
H	4.10	+/-0.30	Voltage DC @ 85C:	4V
K	1.80	nom	Voltage DC @ 105C:	3.3V
F	2.40	+/-0.10	Voltage DC @ 125C:	2.5V
S	1.30	+/-0.30	Temperature Range:	-55/+125C
			Size Code:	E
			Footprint:	7343
			Body Type:	Molded Chip
			Packaging:	T&R
			Package Quantity:	400
			Termination Type:	Tin (Pb free)
			Leakage Current:	40 uA
			Dissipation Factor:	15%
			Impedance @ 100kHz:	0.6 Ohm