




## AK 2 B schwarz/black

Measuring and Testing Equipment:Alligator clips:4 mm safety system

### Product description

Description	Contact-protected, unbreakable crocodile clip. Clamping range up to a bolt diameter of 9.5 mm. The flat section of the clamping jaws allows extremely fine wires to be clamped. 4 mm diameter brass socket connection.
Type	AK 2 B schwarz/black
Order No.	932 435-100
System	4 mm safety system
Clamping range	9.5 mm
Housing Color	black
Other standard types	red color, order no. 932 435-101

### Drawing

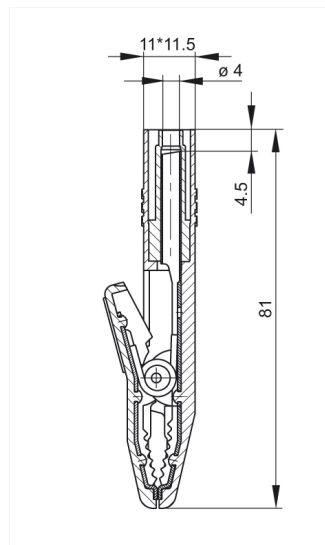

### Technical data

Type of contact	socket
Type of termination	4 mm socket
Standard	IEC 61010
Rated voltage	AC/DC 300 V
Measurement Category	CAT II
Rated current	25 A
Contact resistance	10 mOhm

### Material

Contact material	brass
Contact surface material	nickel-plated
Housing material	PP

### Environmental conditions

Temperature range -25 °C to +80 °C

**Inflammability class**

Housing 94 HB