



fitted with

LED


connected load  
 power consumption  
 luminous flux  
 luminous efficacy  
 light distribution  
 light color  
 color rendering index (CRI)  
 glare-free  
 system of protection  
 class of protection  
 technology  
 usage  
 luminaire body  
 lamp cover  
 tubular sections  
 weight (net)  
 mains lead  
 fastening  
 special features

22-26 V; DC  
 approx. 5 W  
 approx. 460 lm  
 approx. 92 lm/W  
 direct, wide-angled beam  
 neutral white, approx. 5000 K  
 > 70  
 screen  
 IP 67  
 III  
 switchable  
 pressure switch  
 aluminium, painted, black  
 glass screen  
 flexible metal tube, black  
 approx. 1.6 kg (3.5 lbs)  
 approx. 3 m (9.8 ft); with free stranded wires  
 screw-down flange  
 Flood with 30° angle of radiation



**illuminance**

distance: 50 cm  
 Em: 2969 lx  
 Emax: 5298 lx  
 Emin: 1085 lx

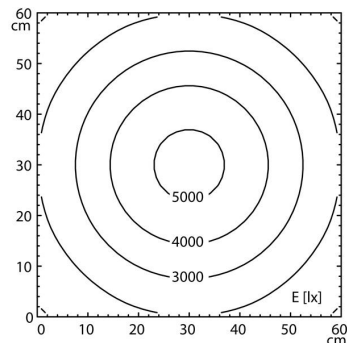

**luminous intensity**

