




Chicago® Grip - Dual Conductor Trans

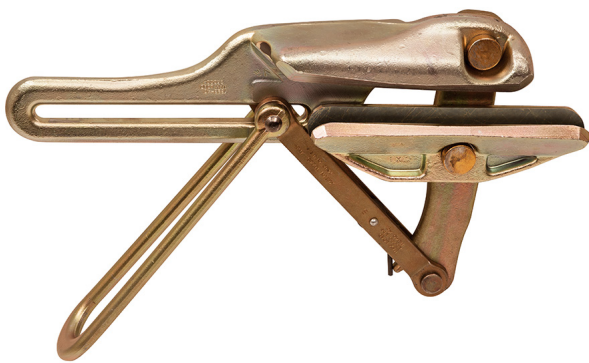

Specifications

Type:	Chicago Grip	Cable Type:	ACSR, AAC
Cable Diameter:	0.95" to 1.27" (24.13 to 32.3)	Hot Latch:	N
Swing Latch:	N	Spring:	N
Locking Handle:	N	Jaw Type:	Round
Maximum Safe Load:	15,000 lb (6803 kg)	Weight:	1.6 oz (45 g)