


Guideway

Innovative & stylish



Escape route signalisation

- Compatible with DALI control unit to control, test & monitor emergency lighting
- Clearly visible in daylight - 500 cd/m²
- Uniform light distribution
- In harmony with interior spaces
- Frameless legend design

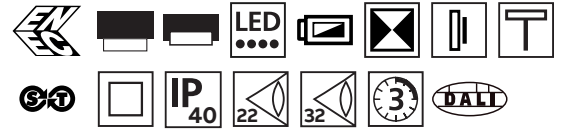

Luminaire

Order code	Description	Input voltage	Lamp type	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
DAEGR3LS1-S22	REC LED SIGN M3 22M DALI	220-240 Vac, 50 Hz	LED strip 1.8W	4.2 / 4.2	M3/NM3	5 - 35	0.93
DAEGR3LS1-S32	REC LED SIGN M3 32M DALI	220-240 Vac, 50 Hz	LED strip 3.6W	6.0 / 6.0	M3/NM3	5 - 35	1.11
DAEG3LS1-S22	LED SIGN M3 22M DALI	220-240 Vac, 50 Hz	LED strip 1.8W	4.2 / 4.2	M3/NM3	5 - 35	1.11
DAEG3LS1-S32	LED SIGN M3 32M DALI	220-240 Vac, 50 Hz	LED strip 3.6W	6.0 / 6.0	M3/NM3	5 - 35	1.58



Includes back to wall mounting accessory as standard.
60 hrs charge at first commissioning, 24 hrs re-charge thereafter.
Maintained and non maintained

Single sided

Part No.	Legends
ISO 7010 legend format	
XEN2EG32	
XEN3EG32	
XEN6EG32	
XEN5EG32	

Flag mounted

Part No.	Legends
ISO 7010 legend format	
XEN602EG32	
XEN603EG32	
XEN606EG32	
XEN605EG32	

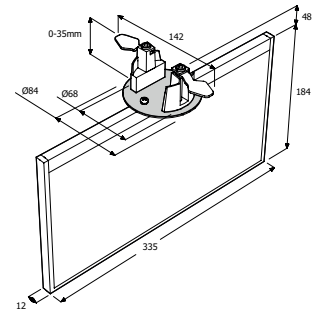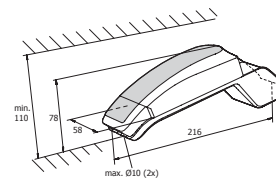

Accessories

Order code	Description	Colour
EG-T4SG	Cover discs, 2+2 self contained	
EG-T4EG	Cover discs, 2+2 slave	

