

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200310046](#)
Status: **Active**
Overview: [Brad Nano-Change \(M8\) Products](#)
Description: Nano-Change (M8) Receptacle, 3 Poles, M8 x 1.0 Mounting Threads, Female (Straight) to 22 AWG Leads, 0.30m (11.81") Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Receptacles
Series	120031
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Nano-Change (M8) Products
Product Name	Nano-Change (M8)
Type	Single Ended (pigtail)
UPC	883906177904

Physical

Coupling Type	Internal Thread
Gender	Female
Keyway	None
Length	0.30m
Material - Component	Nickel-plated Brass
Mounting Thread Size	M8 x 1.0
Net Weight	14.615/g
Orientation	Straight
Panel Mount	Back
Poles	3
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	24
Wire/Cable Type	Leads

Electrical


Current - Maximum per Contact	3.0A
Voltage - Maximum	60V AC / 75V DC

Material Info

Engineering Number	4R3H40E02C3003
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	1200310046-000
---------------	----------------

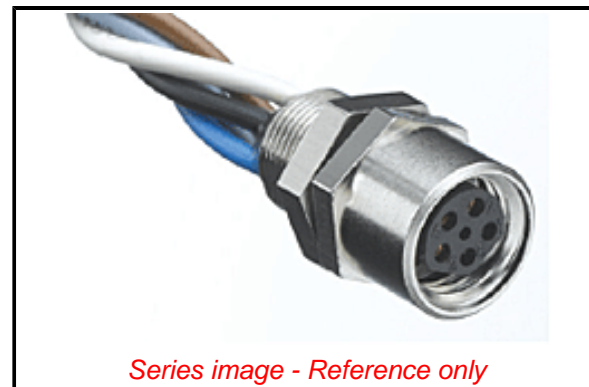

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ECHA_01_2020 (16 January 2020)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[120031 Series](#)