


Alligator clips

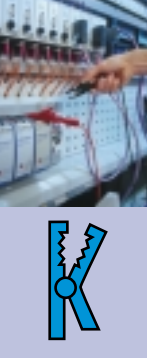

*System Article type	Technical Data	Order no. Colour	Notes
(2)  MA 1 	Clamping range up to 4 mm	930 317-800 ● 930 317-801 ●	
(2)  MA 1 S 	Rust and acid-proof, clamping range up to 4 mm	973 584-100 ● 973 584-101 ●	
(4)  MA 260 SH 	15 A 300 V clamping range ø 6 mm	973 889-100 ● 973 889-101 ●	
(4)  AK 2 B 	25 A 300 V clamping range ø 9.5 mm	932 435-100 ● 932 435-101 ●	
(4)  AK 2 B 2540 I 	34 A clamping range ø 30 mm	972 405-100 ● 972 405-101 ●	

* System: (64) = 0.64 mm system / (2) ≙ 2 mm system / (4) ≙ 4 mm system / (●) ≙ 4 mm safety system / (↔) ≙ 4 mm sliding sleeve system