


Datasheet

**Platinum Resistance Pt100 Hygienic Thermometer, 1.5" Tri-Clamp fitting**

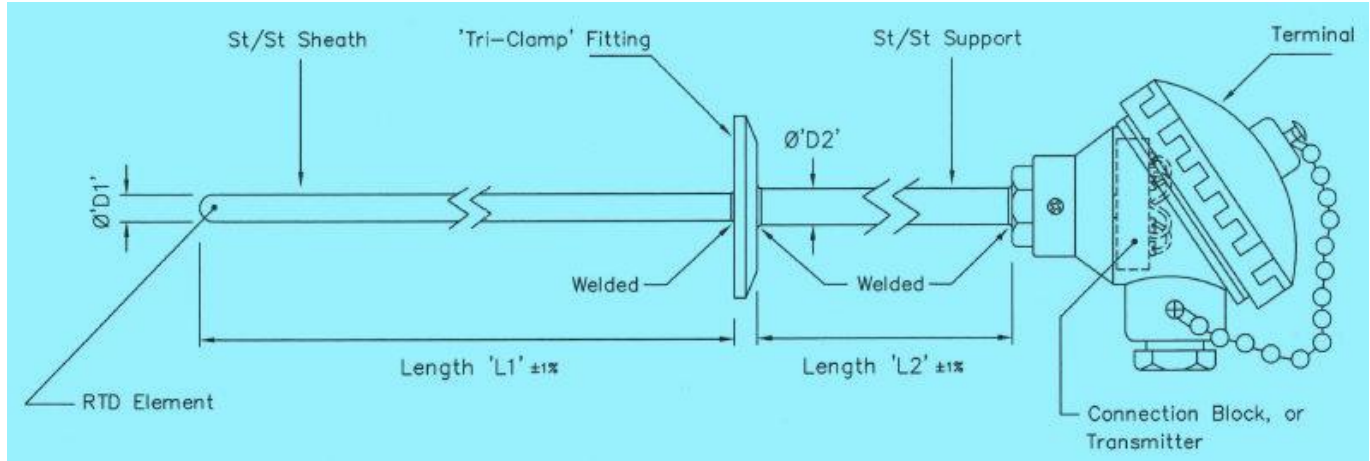

Ideal for hygienic processes including dairy, brewery and pharmaceutical applications.

**Specification**

Sensor Type: Pt100, 3 or 4 wire single element class A  
 Connection Type: 1.5" Tri-Clamp fitting  
 Terminal Head: KNEF  
 Transmitter: Optional SEM-203p transmitter, ranged -50°C to +150°C



Sensor Type	Sheath Diameter (D1)	Sheath Length (L1)	Support Diameter (D2)	Support Length (L2)	Transmitter Fitted	Order Code
Pt100, 4 wire	6.0mm	75mm	8.0mm	50mm	No	<b>XF-1414-FAR</b>
Pt100, 4 wire	6.0mm	125mm	8.0mm	50mm	No	<b>XF-1415-FAR</b>
Pt100, 3 wire	6.0mm	75mm	8.0mm	50mm	Yes	<b>XF-1416-FAR</b>
Pt100, 3 wire	6.0mm	125mm	8.0mm	50mm	Yes	<b>XF-1417-FAR</b>