

Start eco Spot IP44


START ECO SPOT 480lm 840 IP44 DIM WHT

0005377



Product features

- Integrated LED recessed spotlight, vertical tilt 30°, RAL9016 colour, 480lm, 5.5W, phase dimmable trailing/leading edge, 4000K, 38° degree beam angle, polycarbonate white body, low profile 47mm recessed depth, IP44 from the front, IK03, loop-in/loop-out terminals for fast wiring, 86mm bezel diameter, 68-74mm cutout, clear lens. Additional silver bezel included in the packaging. Lifetime: 30.000 hours at L70. Energy Class: A++, A+, A.

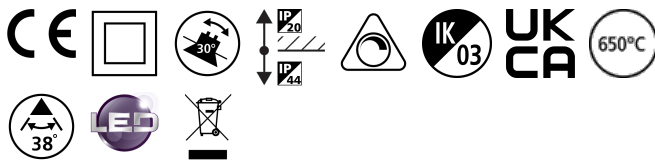

PRODUCT OVERVIEW

IPC Code	0005377
Product name	START ECO SPOT 480lm 840 IP44 DIM WHT
Technology	LED
Housing	PC Polycarbonate
Mount	Ceiling recessed mounting
Environment	Indoor
General application	Residential & Consumer
Certifications	EUNEW008
ETIM Class	EC001744
Fixture luminous flux (lm)	480
Luminaire efficacy (lm/W)	87
Colour temperature (K)	4000
Light colour	Neutral White
CRI (Ra)	80
Colour Variation Initial (SDCM)	6
Beam Angle (°)	38
Photobiological Risk Group	RG0
Total power consumption (W)	5.5
Electrical protection	Class II
Dimmable	Yes
Minimum dimming level (%)	10
LED Flickering Rate	Medium (21% - 40%)
Housing colour	White
IP rating	IP44/20
IK rating	IK03
Product EAN number	5410288053776
Lamps	No
Included lamp	INTEGRATED LED

DATA TABLE

General data

Start eco Spot IP44

START ECO SPOT 480lm 840 IP44 DIM WHT

0005377

IPC Code	0005377
Product name	START ECO SPOT 480lm 840 IP44 DIM WHT
Technology	LED
Housing	PC Polycarbonate
Mount	Ceiling recessed mounting
Environment	Indoor
General application	Residential & Consumer
Operating temperature range (°C)	-10°C - 40°C
Certifications	EUNEW008
ETIM Class	EC001744

Optical data

Fixture luminous flux (lm)	480
Luminaire efficacy (lm/W)	87
Colour temperature (K)	4000
Colour Code	840
Light colour	Neutral White
CRI (Ra)	80
Colour Variation Initial (SDCM)	6
Beam Angle (°)	38
Distribution type	Direct
Photobiological Risk Group	RG0
Lumen maintenance at end of nominal life (%)	70

Electrical data

Total power consumption (W)	5.5
Mains voltage (V)	220-240V~
Lamp power factor	0.85
Electrical protection	Class II
Dimmable	Yes
Minimum dimming level (%)	10
Drive current (mA)	100
Inrush Current (A)	10
Inrush Duration (µs)	200
Glow Wire Test (°C)	650
Nominal Frequency (Hz)	50/60Hz
LED Flickering Rate	Medium (21% - 40%)
Max. Luminaires per 10A C Breaker	60
Max. Luminaires per 13A C Breaker	80
Max. Luminaires per 16A C Breaker	100
Max. Luminaires per 20A C Breaker	120

Lifetime data

Lumen maintenance - L70 B50	30000
-----------------------------	-------

Physical data

Vertical Tilt (°)	30
Housing colour	White

Start eco Spot IP44

START ECO SPOT 480lm 840 IP44 DIM WHT



0005377

IP rating	IP44/20
IK rating	IK03
Diffuser finish	Prismatic
Diffuser material	PMMA Acrylic
Nominal Product Length (mm)	87
Nominal Product Width (mm)	87
Nominal Product Height (mm)	47
Nominal Product Diameter (mm)	87
Weight (kg)	0.087

Packaging

Single packaging type	Carton
Product EAN number	5410288053776
Packaging single length / height (cm)	9.0
Packaging single width (cm)	9.0
Packaging single depth (cm)	5.5
DUN14 (inner)	25410288053770
Units per inner package	6
Packaging inner length / height (cm)	28.5
Packaging inner width (cm)	9.0
Packaging inner depth (cm)	19.0
DUN14 (outer)	15410288053773
Units per outer package	48
Packaging outer length / height (cm)	38.0
Packaging outer width (cm)	24.0
Packaging outer depth (cm)	29.5

PHOTOMETRY

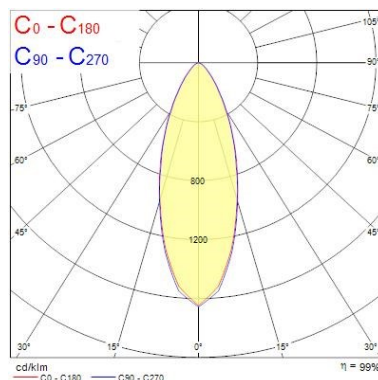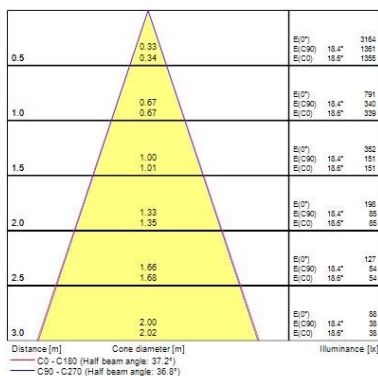


TECHNICAL DRAWINGS

Start eco Spot IP44

START ECO SPOT 480lm 840 IP44 DIM WHT

0005377

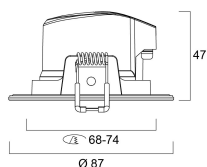


SYLVANIA

0005377



This luminaire
contains built-in LED
lamps

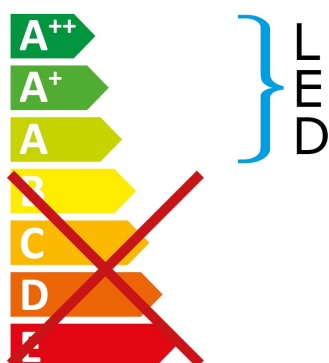

The lamps cannot be
changed in the luminaire.

874/2012



Start eco Spot IP44

START ECO SPOT 480lm 840 IP44 DIM WHT

0005377

