

CABINET LIGHT

CABINET SENSE LINEAR

0053647



Product features

- Battery operated portable light designed for various lighting applications where no suitable electrical socket is available. Uniform light output. Attractive and functional design. Integrated motion and day/night sensor. Low power consumption. Versatile can be used for a wide range of applications like a storage room, safety light, cabinet, night light, caravan, picnic, garage. Auto / On / Off switch. 3xAAA batteries included.



PRODUCT OVERVIEW

IPC Code	0053647
Product name	CABINET SENSE LINEAR
Technology	LED
General application	Residential & Consumer
Certifications	EUNEW009
ETIM Class	EC000987
E-number FI	8709901
Fixture luminous flux (lm)	50
Luminaire efficacy (lm/W)	56
Colour temperature (K)	4000
CRI (Ra)	80
Photobiological Risk Group	RG0
Total power consumption (W)	0.9
Electrical protection	Class III
IP rating	IP20
IK rating	IK03
Product EAN number	5410288536477
Lamps	Yes
Included lamp	INTEGRATED LED

DATA TABLE

General data

IPC Code	0053647
Product name	CABINET SENSE LINEAR
Technology	LED
General application	Residential & Consumer
Certifications	EUNEW009
ETIM Class	EC000987
E-number FI	8709901

Optical data

Fixture luminous flux (lm)	50
Luminaire efficacy (lm/W)	56

CABINET LIGHT

CABINET SENSE LINEAR

0053647

Colour temperature (K)	4000
CRI (Ra)	80
Photobiological Risk Group	RG0

Electrical data

Total power consumption (W)	0.9
Mains voltage (V)	4.5V
Electrical protection	Class III
Drive current (mA)	200
Nominal Frequency (Hz)	DC

Lifetime data

Lumen maintenance - L70 B50	25000
-----------------------------	-------

Physical data

IP rating	IP20
IK rating	IK03
Nominal Product Length (mm)	250
Nominal Product Width (mm)	25
Nominal Product Height (mm)	30
Weight (kg)	0.149

 
Packaging

Single packaging type	Carton
Product EAN number	5410288536477
Packaging single length / height (cm)	31.5
Packaging single width (cm)	20.0
Packaging single depth (cm)	4.0
DUN14 (inner)	25410288536471
Units per inner package	6
Packaging inner length / height (cm)	32.5
Packaging inner width (cm)	21.5
Packaging inner depth (cm)	22.0
DUN14 (outer)	15410288536474
Units per outer package	24
Packaging outer length / height (cm)	45.0
Packaging outer width (cm)	34.5
Packaging outer depth (cm)	46.5

Safety data


Safety message	Not Suitable for totally enclosed fixtures
----------------	--

TECHNICAL DRAWINGS




CABINET LIGHT CABINET SENSE LINEAR 0053647


SYLVANIA 0053647




This luminaire contains built-in LED lamps

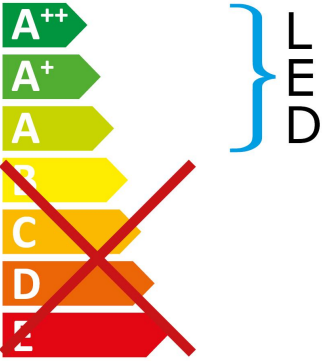


The lamps cannot be changed in the luminaire.


874/2012 



This luminaire contains built-in LED lamps

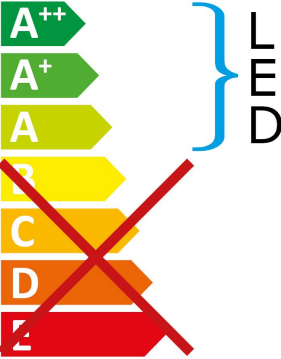

The lamps cannot be changed in the luminaire.

SYLVANIA 0053647 

874/2012