

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301460082](#)  
**Status:** **Active**  
**Overview:** [Watertite Wet-Location Wiring Solutions](#)  
**Description:** Watertite Extreme Plug with Locking Blade, 2 Pole/3 Wire, NEMA L5-15, 125V, Cord Grip Body Size F2, Silicone Husk

**Documents:**

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E10176

**General**

Product Family [Wiring Devices](#)  
 Series [130146](#)  
 IP Rating [IP69K](#)  
 NEMA Configuration [NEMA L5-15](#)  
 Overview [Watertite Wet-Location Wiring Solutions](#)  
 Product Name [Watertite Extreme](#)  
 Receptacle Type [N/A](#)  
 Specialty [N/A](#)  
 Type [Plug](#)  
 UPC [78678871202](#)

**Physical**

Cord Grip Body Size [F2 1/2"](#)  
 Flange [No](#)  
 Flip Lid [No](#)  
 Gender [Male](#)  
 Length [N/A](#)  
 Locking Blade [Yes](#)  
 Net Weight [126.552/g](#)  
 Poles [2-pole/3-wire](#)

**Electrical**


Cord Type [N/A](#)  
 Current - Maximum per Contact [15.0A](#)  
 GFCI [No](#)  
 Lighted Connector [No](#)  
 Voltage - Maximum [125V](#)

**Material Info**

Engineering Number [24W47](#)

**Reference - Drawing Numbers**

Sales Drawing [1301460082-000](#)

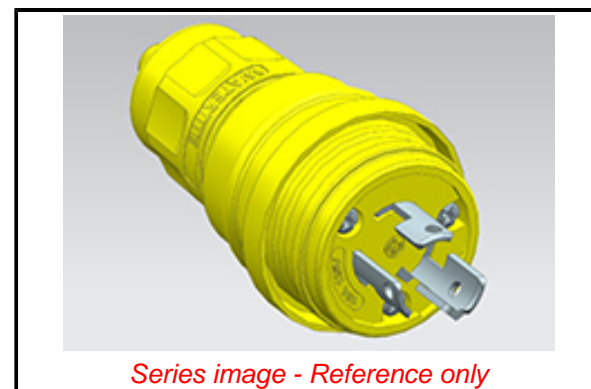

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[130146 Series](#)