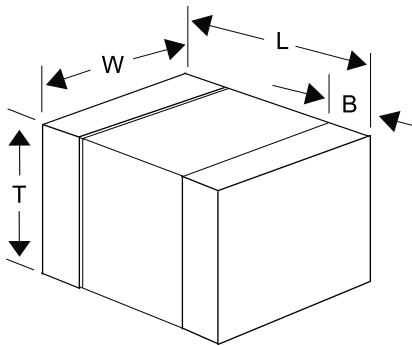


KEMET, Z-SMS, Ferrite Beads, Noise Suppression, 400 mOhms

**Dimensions**

Chip Size	0201
L	0.6mm +/-0.03mm
W	0.3mm +/-0.03mm
T	0.3mm +/-0.03mm
B	0.15mm +/-0.05mm

Packaging Specifications

Packaging:	T&R
Packaging Quantity:	15000

General Information

Series:	Z-SMS
Style:	SMD Chip
Description:	Chip Bead Signal Line
Features:	Increases The Z Characteristics Sharply Above 20MHz And Is Applicable For Radiated Noise In The 100MHz-300MHz Range, Especially Effective On Video Signals
RoHS:	Yes

Specifications

Impedance:	60 Ohms (100 mHz)
Impedance Tolerance:	25%
Ripple Current:	200 mA (MAX)
Temperature Range:	-55/+125°C
Resistance:	0.4 Ohms