



TECHNICAL INFORMATION

Watts:	12
Lumens:	600
Input Power:	AC:100-240V, 50/60Hz
Long Life:	30,000 Hours
Unit Color:	Grey
Body Type:	PC
PF:	>0.9
LED Chip Type:	SMD 2835
CRI:	>80
Operation Temperature:	-20°C to +45°C
Dimmable:	No
Beam Angle:	110°
Color:	4000K
Dimension:	265x120x81mm


LANDSCAPE SOFT LIGHTS

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 8234 - 1295 939

[View more details](#)

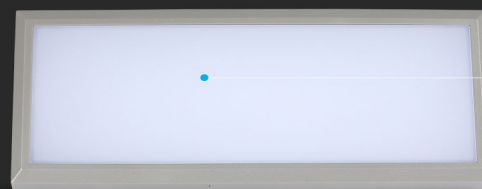

SMD LED'S



Uses premium quality LEDs for a reliable, long-lasting, and energy saving light



FEATURES

- Splendid designs made of high endurance PC material
- Ingress protection: {ip_rating}
- Excellent heat dissipation
- Fitted with high quality SMD 2835 chips for better reliability and longer lifespan
- Perfect lighting option for landscapes, gardens, patios etc.
- Recommended daily usage: 10 - 12 hours *Exceeding recommended daily usage will void warranty

CE/EMC

CE/LVD



PACKAGING

Gross Weight (Kgs):	0.501
Unit CBM:	0.0020475
Dimension:	265x120x81mm

MASTER BOX PACKAGING

Box Qty:	20
Qty Per Pallet:	480
Length (Box) mm:	175
Width (Box) mm:	130
Height (Box) mm:	90

LISTING DETAILS

Commodity Code:	9405403990
EanCode:	3800157625746