



TECHNICAL INFORMATION

Watts:	20
Lumens:	1000
Input Power:	AC:100-240V, 50/60Hz
Long Life:	30,000 Hours
Unit Color:	Grey
Body Type:	PC
PF:	>0.9
LED Chip Type:	SMD 2835
CRI:	>80
Operation Temperature:	-20°C to +45°C
Dimmable:	No
Beam Angle:	110°
Color:	4000K
Dimension:	319x170x114mm


LANDSCAPE SOF LIGHTS

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 8237 - 931 939

[View more details](#)

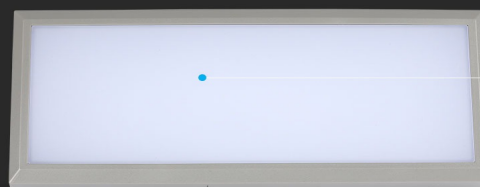

SMD LED'S



80%
ENERGY
SAVING

Uses premium quality LEDs for a reliable, long-lasting, and energy saving light



IP65
RATING



2 YEAR
WARRANTY



80%
ENERGY
SAVING



CRI>80

FEATURES

- Splendid designs made of high endurance PC material
- Ingress protection: {ip_rating}
- Excellent heat dissipation
- Fitted with high quality SMD 2835 chips for better reliability and longer lifespan
- Perfect lighting option for landscapes, gardens, patios etc.
- Recommended daily usage: 10 - 12 hours *Exceeding recommended daily usage will void warranty

CE/EMC

CE/LVD



PACKAGING

Gross Weight (Kgs): 0.833

Unit CBM: 0.00664125

Dimension: 319x170x114mm

MASTER BOX PACKAGING

Box Qty: 20

Qty Per Pallet: 180

Length (Box) mm: 325

Width (Box) mm: 175

Height (Box) mm: 100

LISTING DETAILS

Commodity Code: 9405403990

EanCode: 3800157625777