

TECHNICAL INFORMATION

Lumens:	2450
Input Power:	DC:6.4V
Long Life:	20,000 Hours
Unit Color:	Black
Body Type:	Aluminium
LED Chip Type:	SMD
CRI:	>70
Operation Temperature:	-20°C to +45°C
Dimmable:	No
Beam Angle:	120°
Color:	4000K
Dimension:	325x85x280mm
Battery Type:	15000mAh
Charging Time:	4 Hours
Working Time:	8 Hours
Solar Panel:	35W



FEATURES

- Solar Powered Floodlight - Zero electricity cost.
- Designed with Remote control, Auto and timer function.
- Flexible installation, designed with solar panel with 5 meter wire length
- Perfectly built for outdoor with Ingress protection of IP65
- Suitable for Pathways, Garden, Patio and similar outdoor environment

CE/EMC

CE/LVD




SOLAR FLOODLIGHTS

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 8576 - 938

[View more details](#)

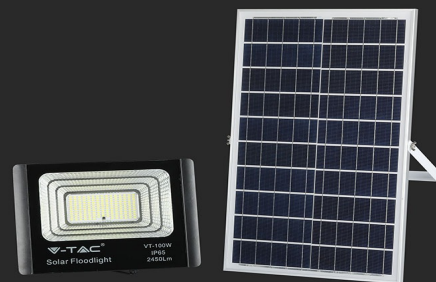

ZERO ELECTRICITY COST

FULLY SOLAR POWERED

**EASY INSTALLATION
NO WIRING**

**5
METER
WIRE**

PACKAGING

Gross Weight (Kgs):	5.469
Unit CBM:	0.026196
Dimension:	325x85x280mm

MASTER BOX PACKAGING

Box Qty:	2
Qty Per Pallet:	40
Length (Box) mm:	120
Width (Box) mm:	370
Height (Box) mm:	590

LISTING DETAILS

Commodity Code:	9405403990
EanCode:	3800157645614