



## TECHNICAL INFORMATION

Lumens:	550
Input Power:	DC:6V
Long Life:	20,000 Hours
Unit Color:	Black
LED Chip Type:	SMD
Operation Temperature:	-20°C to +45°C
Dimmable:	No
Color:	6000K
Battery Type:	5000mAh
Solar Panel:	12W



## FEATURES

- Solar Powered Floodlight - Zero electricity cost.
- Designed with Remote control, Auto and timer function.
- Flexible installation, designed with solar panel with 5 meter wire length
- Perfectly built for outdoor with Ingress protection of IP65
- Suitable for Pathways, Garden, Patio and similar outdoor environment

CE/EMC

CE/LVD



## SOLAR FLOODLIGHTS | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide extended multi-year warranty on our products, as well as detailed support.


*One brand, endless solutions..*

SKU: 94006 - 938

[View more details](#)



## REMOTE CONTROL AUTO AND TIMER FUNCTION

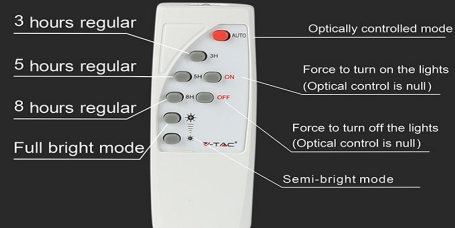

## PACKAGING

Gross Weight (Kgs): 1.867  
Unit CBM: 0.00532

## MASTER BOX PACKAGING

Box Qty: 8  
Qty Per Pallet: 320  
Length (Box) mm: 80  
Width (Box) mm: 190  
Height (Box) mm: 350

## LISTING DETAILS

EanCode: 3800157645744