



## TECHNICAL INFORMATION

Wireless Frequency:	2.4Ghz
Watts:	10
Equivalence Watts:	60
Color:	RGB+3IN1
Lumens:	806
Beam Angle:	200°
Shape:	A60
Dimmable:	Yes
Input Power:	AC:220-240V, 50Hz
Long Life:	30,000 Hours
Unit Color:	White
Body Type:	Thermoplastic
Dimension:	60x120mm
PF:	>0.5
CRI:	>80
Operation Temperature:	-20°C to +45°C



## FEATURES

- Wi-Fi enabled smart lamp
- Easy to install and pair with the V-TAC Smart Light App
- 2.4Ghz Wi-Fi frequency
- Switch lights off, change colours, dim the lights and more using the V-TAC app
- Wireless standard: IEEE 802.11 b/g/n
- Can be controlled via V-TAC Smart Light app or Alexa and Google Home
- Suitable for residential, commercial, living rooms, bedrooms, hotels etc.
- Recommended daily usage: 10 - 12 hours \*Exceeding recommended daily usage will void warranty


## BULBS SMART LIGHT

WiFi-supported home solutions to convert any device into a smart device, and ultimately convert any home into a smart home. Have a systematic, unified control on all your smart devices through the official V-TAC app, Amazon Alexa, and Google Home.

*One brand, endless solutions..testing*

SKU: 2751 - 930 940

[View more details](#)

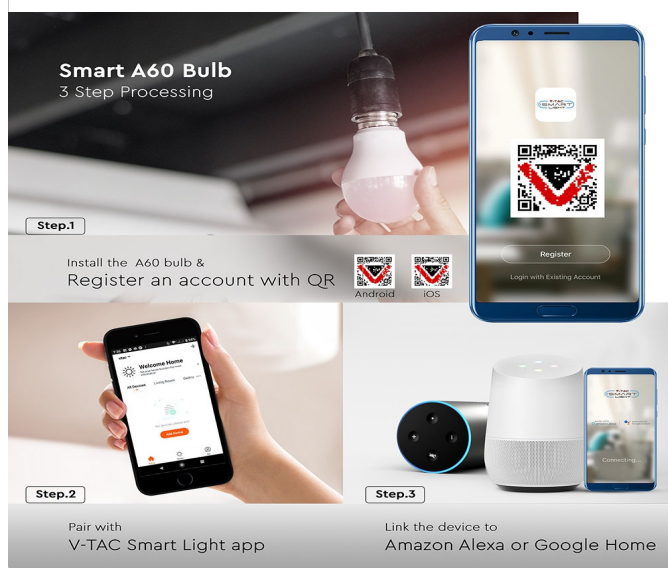

## PACKAGING

Gross Weight (Kgs): 0.064  
Unit CBM: 0.000507  
Dimension: 60x120mm

## MASTER BOX PACKAGING

Box Qty: 100  
Qty Per Pallet: 2500  
Length (Box) mm: 65  
Width (Box) mm: 65  
Height (Box) mm: 120

## LISTING DETAILS

Commodity Code: 9405403990  
EanCode: 3800157646628