



18.5" LED Monitor 1366x768

83-17270

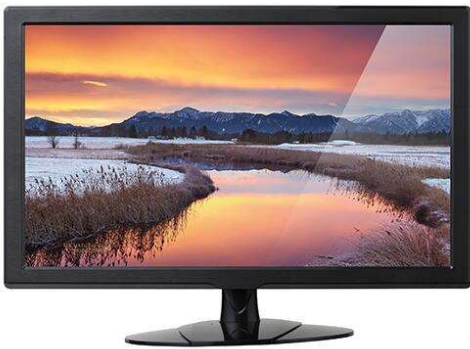

Dimension

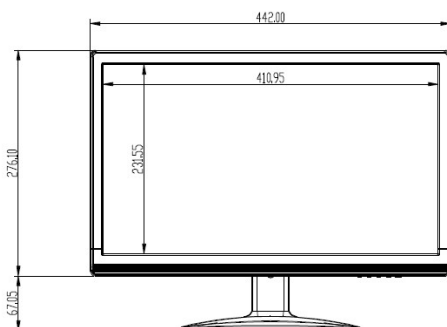

Accessories

- VGA Cable
- Audio Cable
- Power Cable
- Manual

Specifications

Panel	
Size	18.5" LED-Backlit
Resolution	1366x768
Color Support	16.7M
Brightness	220cd/m ²
Contrast Ratio	1000:1
Response Time	5ms
Speaker(optional)	2x2w
I/O	
VGA IN	X1
DVI IN	X1(optional)
HDMI IN	X1(optional)
Audio IN	X1
Power	
Consumption	<20W(on),0.5W(off)
Power Supply	Internal
Voltage	100-240V AC,60/50Hz
Operating Condition	
Temperature	0°C - 40°C
Humidity	10%-80%
Others	
VESA	100x100mm
Box Dimension (L*W*H)	492x113x485mm
Loading Quantity (With Pallets)	20GP:1160 pcs
	40GP:2436 pcs
	40HQ:2772 pcs
Gross Weight	3.2Kgs
MOQ	500
Approvals	CE / FCC