


**SPECIFICATION  
CONTROL DRAWING  
Crystal Resonator**

**FREQUENCY**

**1.843200MHz**

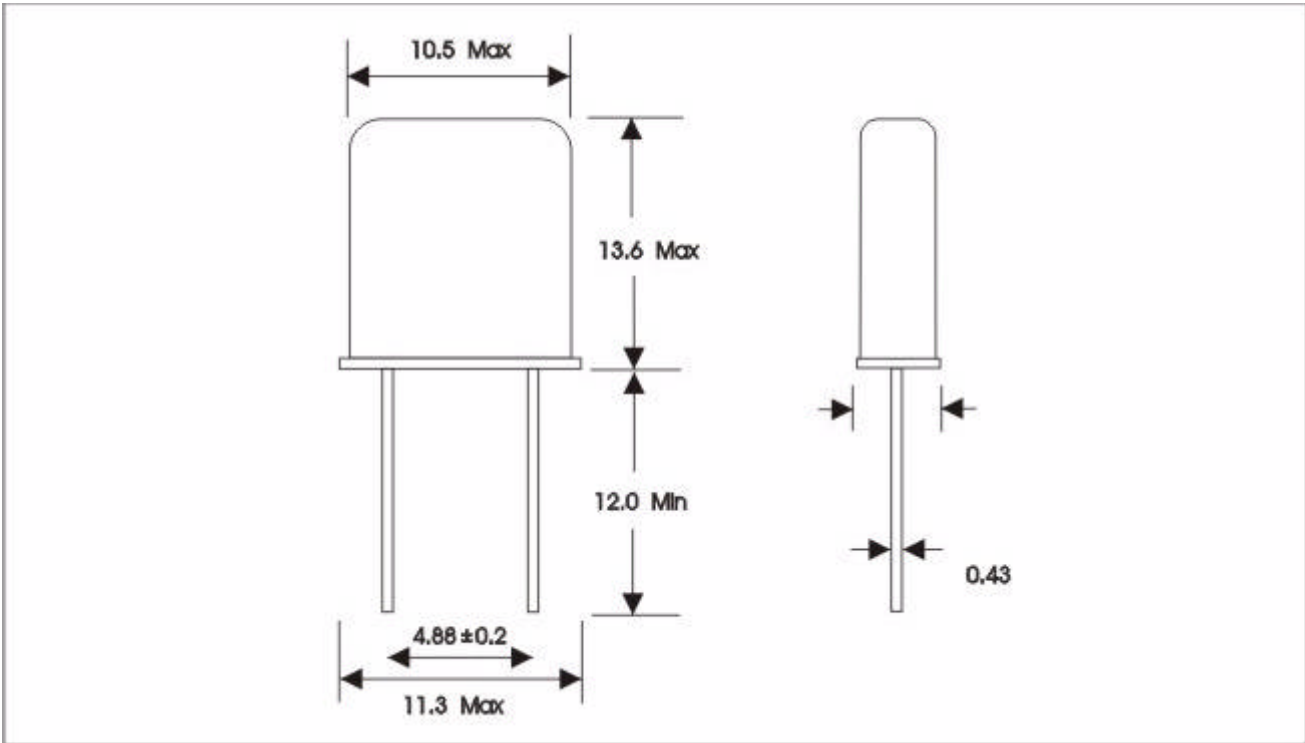

Holder Style	HC-49/U
Mode	Fundamental
Adjustment Tolerance	± 20PPM at 25°C
Temperature Stability	± 30 PPM
Operating Temp. Range	-10°C to +60°C
Load Capacitance	12 pF
ESR	100 Ohm
Marking	Mark AELX064L\FREQ+WWYY

Amdt Date	Change Note	AEL Code	
		X1M843200L010	
		<b>Issue Ref</b>	A