


VERTICAL PDU SWITCHED ANGLED RIGHT DIMENSIONS

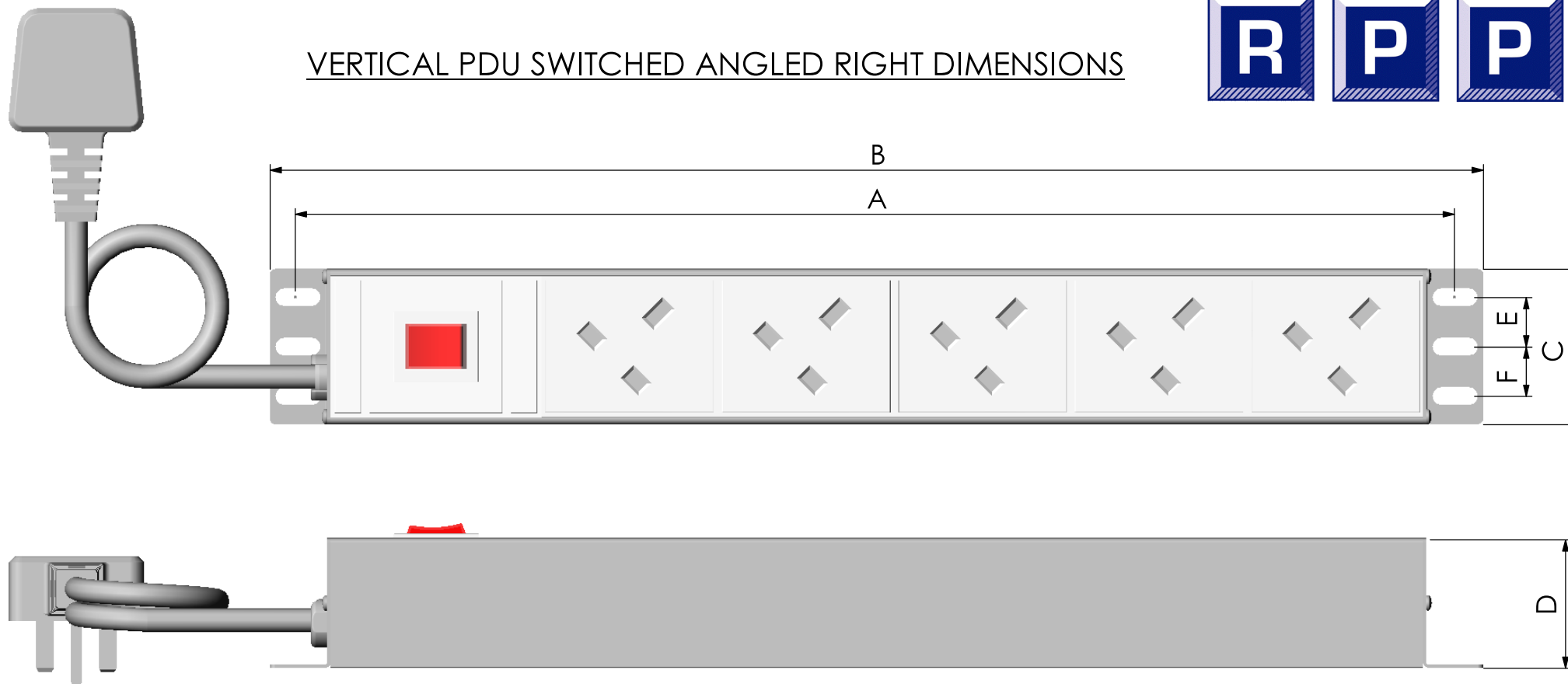

TYPE	A	B	C	D	E	F
XAR4S	347.5	367.5	55	46	21.35	21.35
XAR5S	409.5	429.5	55	46	21.35	21.35
XAR6S	472.5	492.5	55	46	21.35	21.35
XAR8S	597	617	55	46	21.35	21.35
XAR10S	722	742	55	46	21.35	21.35
XAR12S	847	867	55	46	21.35	21.35
XAR15S	1035	1055	55	46	21.35	21.35
XAR20S	1347	1367	55	46	21.35	21.35