


**SPECIFICATION
CONTROL DRAWING
Crystal Resonator**

FREQUENCY
4.000000MHz

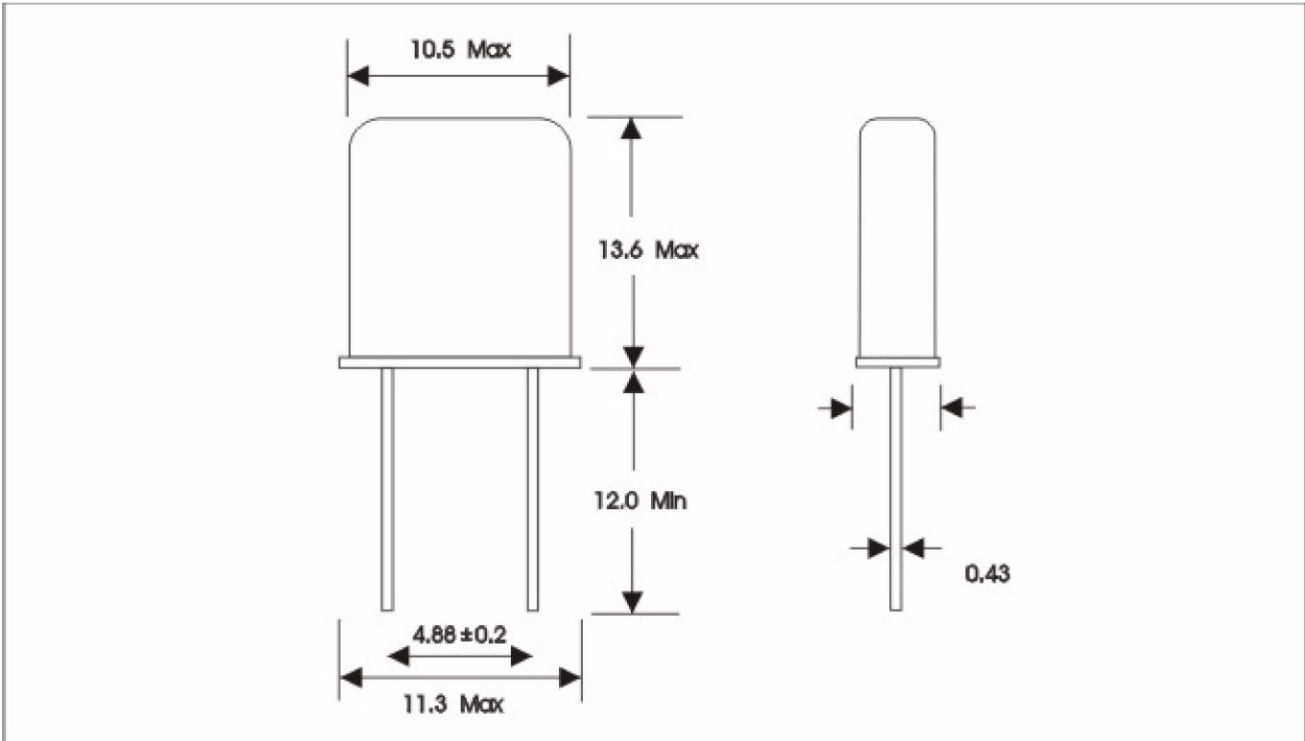

Holder Style	HC-49/U
Mode	Fundamental
Adjustment Tolerance	± 30PPM at 25°C
Temperature Stability	± 50 PPM
Operating Temp. Range	-10°C to +60°C
Load Capacitance	30 pF
ESR	90 Ohm
Marking	Mark AELX009L\FREQ+WWYY

Amdt Date	Change Note	AEL Code
		X4M000000L009
		Issue Ref
		A