


**SPECIFICATION
CONTROL DRAWING
Crystal Resonator**

FREQUENCY
4.194304MHz

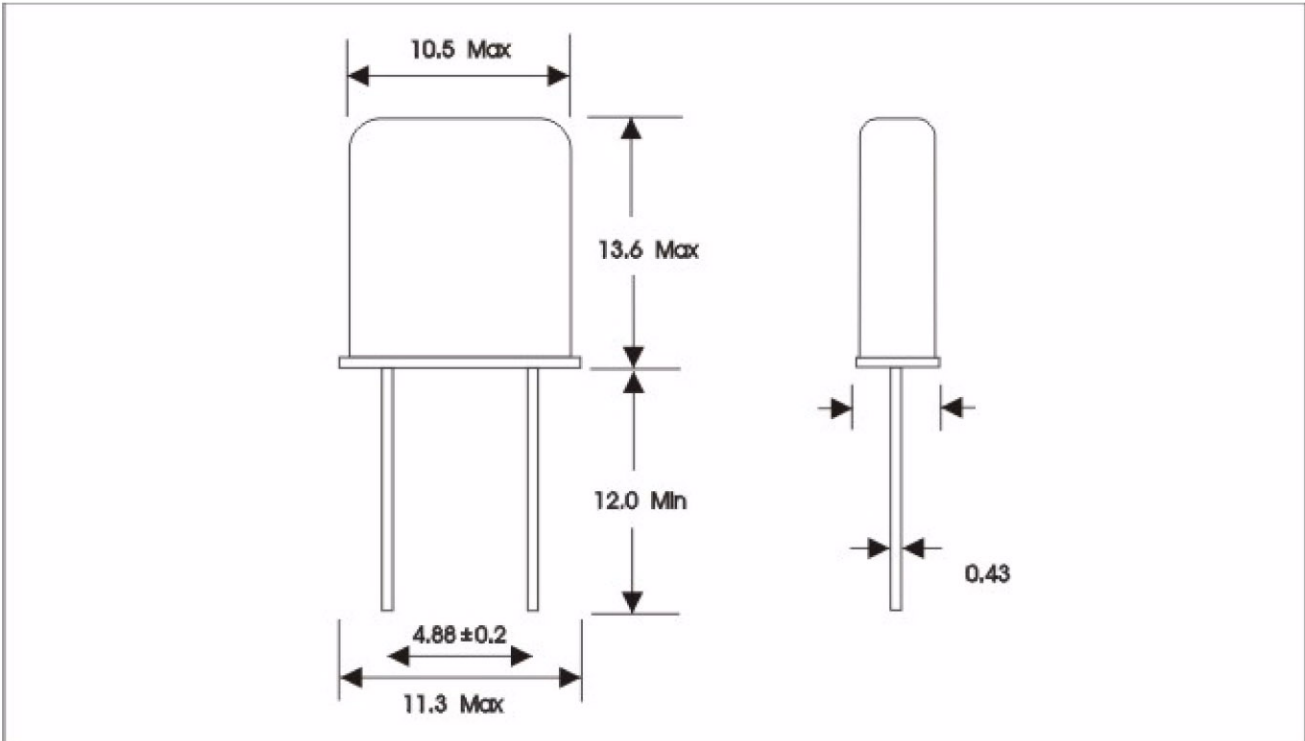

| | |
|-----------------------|-------------------------|
| Holder Style | HC-49/U |
| Mode | Fundamental |
| Adjustment Tolerance | ± 20PPM at 25°C |
| Temperature Stability | ± 50 PPM |
| Operating Temp. Range | -10°C to +60°C |
| Load Capacitance | 12 pF |
| ESR | 100 Ohm |
| Marking | Mark AELX063L\FREQ+WWYY |

| Amdt Date | Change Note | AEL Code | |
|-----------|-------------|------------------|---|
| | | X4M194304L063 | |
| | | Issue Ref | A |