


**SPECIFICATION  
CONTROL DRAWING  
Crystal Resonator**

FREQUENCY
5.000000MHz

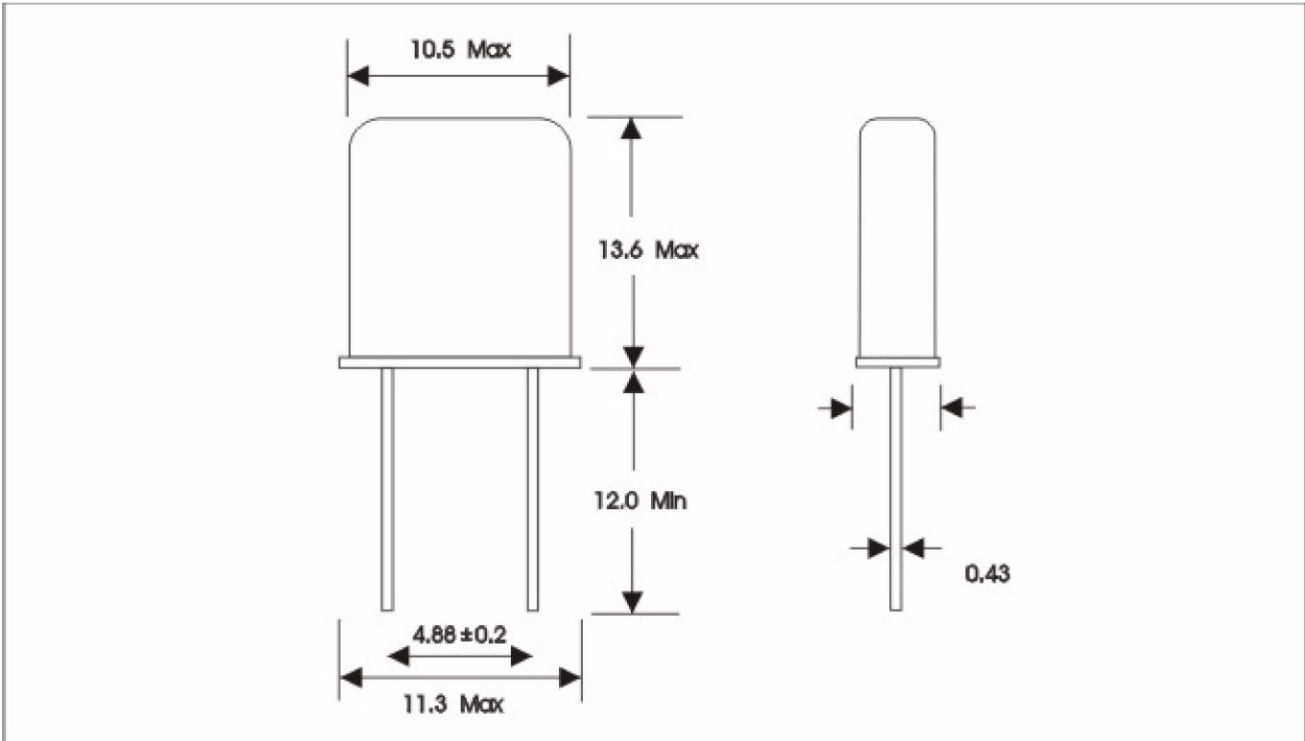

Holder Style	HC-49/U
Mode	Fundamental
Adjustment Tolerance	± 30PPM at 25°C
Temperature Stability	± 50 PPM
Operating Temp. Range	-10°C to +60°C
Load Capacitance	30 pF
ESR	50 Ohm
Marking	Mark AELX001L\FREQ+WWYY

Amdt Date	Change Note	AEL Code	
		X5M000000L001	
		Issue Ref	A