



# Einhell

## EXPERT PLUS



### Cl. Polishing/Sanding Machine

### CE-CP 18/180 Li E-Solo

Item No.: 2093320

Ident No.: 11018

Bar Code: 4006825638998

The Einhell CE-CP 18/180 Li E-Solo cordless polishing and sanding machine is a member of the Power X-Change series. It is powered by a long-lasting brushless motor. Polishing and sanding with a single tool: A large polishing disk with a 180mm ensures speedy progress. For comfortable operation there is electronic speed control via LCD, an ergonomic handle for an optimum grip and controlled handling, as well as the slimline design with softgrip. The hook-and-loop fastener enables attachments to be changed quickly. For problem-free fastening of the polishing disk there is a spindle locking system. This product comes without a battery or charger. For optimum results the use of the 2.6 Ah Plus rechargeable battery or higher is recommended.

## Features & Benefits

- A member of the Power X-Change family, 1x18V battery required
- Einhell brushless electric motor
- 2-in-1 product: Polishing and grinding/sanding with a single tool
- Electronic speed control via LCD
- Ergonomic handle for an optimum hold and controlled operation
- Slimline design with ergonomic softgrip surfaces
- Hook-and-loop fastener for changing the attachments quickly
- Spindle locking system for easy attachment of the polishing disk
- Large polishing disk with 180 mm diameter for speedy progress
- Recommendation for optimum results: 2.6 Ah rechargeable battery
- Supplied without battery and charger (available separately)






## Technical Data

- Rotation speed 500 - 3000 min<sup>-1</sup>
- Diameter of sanding plate 180 mm

## Logistic Data

- Product weight (kg) 1.28
- Gross weight (kg) 2.46
- Dimensions single plackaging 370 x 200 x 135 mm
- Pieces per export carton 4 Pieces
- Gross weight of export carton 9.69 kg
- Dimensions export carton 420 x 390 x 290 mm
- Container quantity (20"/40"/40"HC) 2188 | 4800 | 5640

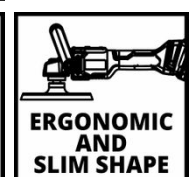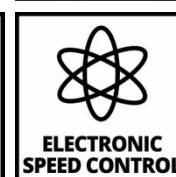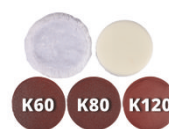

## Available as special accessories



18V 30min Power X-Change  
Charger  
Item No.: 4512011  
Bar Code: 4006825587029  
Einhell Accessory



18V 5,2 Ah P-X-C Plus  
Battery  
Item No.: 4511437  
Bar Code: 4006825616606  
Einhell Accessory



Power-X-Boostcharger 6 A  
Charger  
Item No.: 4512064  
Bar Code: 4006825629019  
Einhell Accessory



Power-X-Twincharger 3 A  
Charger  
Item No.: 4512069  
Bar Code: 4006825629729  
Einhell Accessory



Polier-/Schl. CE-CP 18/180 Li  
Autotechnique Accessory  
Item No.: 2093233  
Bar Code: 4006825551846  
Einhell Accessory



18V 3,0Ah PXC Starter Kit  
PXC-Starter-Kit  
Item No.: 4512041  
Bar Code: 4006825613698  
Einhell Accessory



18V 4,0Ah PXC Starter Kit  
PXC-Starter-Kit  
Item No.: 4512042  
Bar Code: 4006825613704  
Einhell Accessory



18V 4,0 Ah Power-X-Change  
Battery  
Item No.: 4511396  
Bar Code: 4006825610376  
Einhell Accessory

## Battery-Running-Times

running time (in min.)

Usage	running time	
Unit of measure	min.	
with 1.5 Ah PXC	17	<div style="width: 17%; height: 15px; background-color: red;"></div>
with 2 Ah PXC	20	<div style="width: 20%; height: 15px; background-color: red;"></div>
with 2.5 Ah PXC	25	<div style="width: 25%; height: 15px; background-color: red;"></div>
with 2.6 Ah PXC+	27	<div style="width: 27%; height: 15px; background-color: red;"></div>
with 3 Ah PXC	35	<div style="width: 35%; height: 15px; background-color: red;"></div>
with 3.0 Ah PXC+	35	<div style="width: 35%; height: 15px; background-color: red;"></div>
with 4 Ah PXC	43	<div style="width: 43%; height: 15px; background-color: red;"></div>
with 5.2 Ah PXC+	54	<div style="width: 54%; height: 15px; background-color: red;"></div>
with 4-6 Ah PXC+ (4 Ah mode)	43	<div style="width: 43%; height: 15px; background-color: red;"></div>
with 4-6 Ah PXC+ (6 Ah mode)	65	<div style="width: 65%; height: 15px; background-color: red;"></div>
best performance with min.	2.5 Ah	
reason for best performance recommendation	current	