


Datasheet

BS Type 'KX' Glassfibre Extension Thermocouple Cable

Choice of 1/0.3mm flat pair or 7/0.2mm with stainless steel overbraid

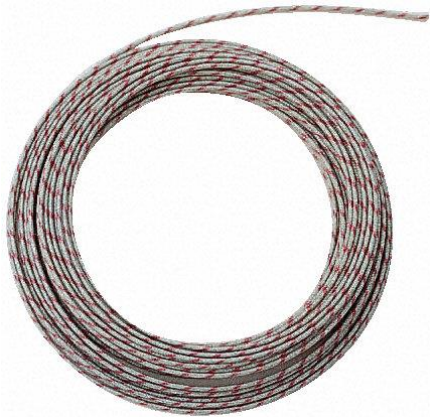

1/0.3mm



7/0.2mm

- 'KX' extension cable with Chromel/Alumel conductors for extending 'K' type thermocouples
- Glassfibre insulated flat pair construction
- Conductors laid flat, Glassfibre insulated with Glassfibre overall, silicone varnished throughout
- Good temperature resistance but not suitable where fluids are present
- Solid 1/0.3mm or 7/0.2mm version with stainless steel overbraid for added mechanical strength and durability
- Available in 5, 10, 25 & 50 metre lengths
- Tolerance Class 2
- Insulation rating -60°C to 350°C (short periods up to 400°C)
- Colour code (cores & jacket) to former British Standard – BS1843-1952

T/C Type	Conductors	Cores	Jacket	St/Steel Braid	Reel Length	Manufacturers Code	Order Code
KX	1/0.315mm	+Brown/-Blue	Red	No	5 metres	WK-041-D	XF-1637-FAR
KX	1/0.315mm	+Brown/-Blue	Red	No	10 metres	WK-041-D	XF-1640-FAR
KX	1/0.315mm	+Brown/-Blue	Red	No	25 metres	WK-041-D	XF-1638-FAR
KX	1/0.315mm	+Brown/-Blue	Red	No	50 metres	WK-041-D	XF-1639-FAR
KX	7/0.2mm	+Brown/-Blue	Red	Yes	5 metres	WK-075-D	XF-1641-FAR
KX	7/0.2mm	+Brown/-Blue	Red	Yes	10 metres	WK-075-D	XF-1644-FAR
KX	7/0.2mm	+Brown/-Blue	Red	Yes	25 metres	WK-075-D	XF-1642-FAR
KX	7/0.2mm	+Brown/-Blue	Red	Yes	50 metres	WK-075-D	XF-1643-FAR