

UTILITY 40W LED LIGHT PANEL NON-DIMMABLE IN DAYLIGHT

SPECIFICATION SHEET

PRODUCT CODE: 769602

- Aluminium frame with PMMA diffuser.
- Supplied with plug & play driver.
- Compatible with universal emergency modules.
- Even distribution of flicker free light.
- Easy installation, no mounting kit required.
- Simple retrofit directly onto T-bar ceiling grids
- Ultra slim 9mm design
- Lightweight 2.5kg
- Maintenance free



LIGHT PANEL



350W
EQUIVALENT



3200
LUMENS



110°
BEAM
ANGLE



NON-
DIMMABLE



40,000 HOURS
LIFESPAN



5 YEARS
WARRANTY



 

ENERGY
RATING

SPECIFICATION


Product code	764619
Fitting	Panel
Bulb Shape	SMD
Wattage	40W
Equivalent wattage	350W
Lumens	3200lm
Ra	80
Dimmable	No
Beam Angle	110°
Length	595mm
Width	595mm
Depth	9mm
Lifespan	40,000 hours
Warranty	5 Years
Energy consumption	40kWh/1000h
Input Frequency	50Hz
Voltage	220-240V
Energy rating	A+
Material	
Packaging	Brown Box + Colour Sticker
IP Rating	IP20

OPTICAL TEST PARAMETERS

Voltage	220-240V
Power	40W
Colour tolerance	<6
Power factor	0.9

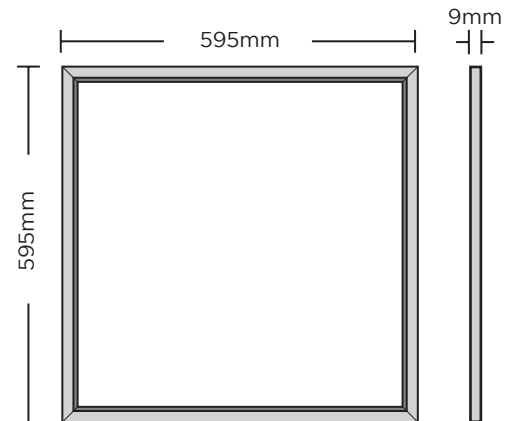

220-240V

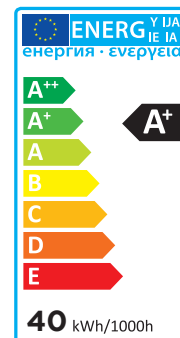

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT
T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk



February 2020