


COMMA 10W LED OUTDOOR OVAL BULKHEAD

SPECIFICATION SHEET

PRODUCT CODE: 778258

With its sturdy casing and black finish, the 10W LED Outdoor Oval Bulkhead offers a superb outside lighting solution for a variety of domestic and commercial installations. The bulkhead boasts a 15,000-hour lifespan and has a wide 120° beam angle spreading the light out. Coupled with an 850-lumen light output, the final product is a space full of bright light. This bulkhead comes fully IP65 rated, meaning the durable casing is perfect for enduring any weather.



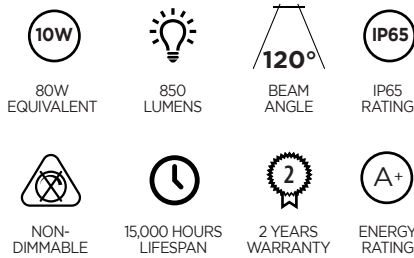


SPECIFICATION

Product code	778258
Fitting	Bulkhead
Bulb shape	SMD
Wattage	10W
Equivalent wattage	80W
Lumens	850lm
Ra	80
Dimmable	No
Beam Angle	120°
Width	170mm
Height	88mm
Depth	69mm
Lifespan	15,000 hours
Warranty	2 Years
Energy consumption	10kWh/1000h
Input frequency	50Hz
Voltage	220-240V
Energy rating	A+
Material	PC Body + Cover
Packaging	White Box + Colour Label
IP Rating	IP65

OPTICAL TEST PARAMETERS

Voltage	220-240V
Current	0.074A
Power	10.05W
CCT	No
Ra	80
Lumens	862lm
Lumens per watt	80lm/W
Colour tolerance	<6
Power factor	0.5

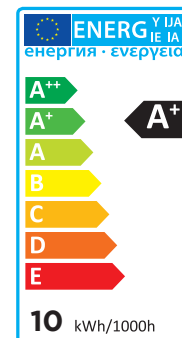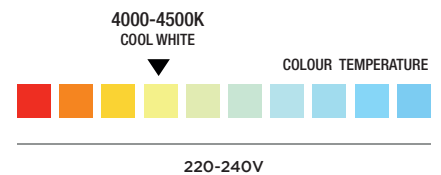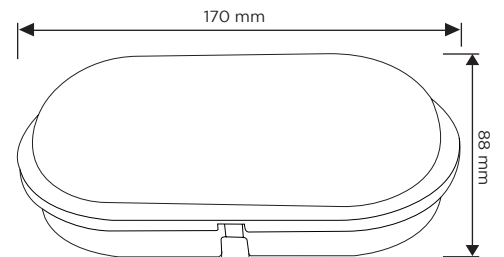

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT

T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk



October 2019