

COMMA 30W LED OUTDOOR ROUND BULKHEAD

SPECIFICATION SHEET

PRODUCT CODE: 778296

With its sturdy casing and black finish, the 30W LED Outdoor Round Bulkhead offers a superb outside lighting solution for a variety of domestic and commercial installations. The bulkhead boasts a 15,000-hour lifespan and has a wide 120° beam angle spreading the light out. Coupled with a 2400-lumen light output, the final product is a space full of bright light. This bulkhead comes fully IP65 rated, meaning the durable casing is perfect for enduring any weather.



240W
EQUIVALENT



2400
LUMENS



BEAM
ANGLE



IP65
RATING



NON-
DIMMABLE



15,000 HOURS
LIFESPAN



2 YEARS
WARRANTY






ENERGY
RATING

SPECIFICATION

Product code	778296
Fitting	Bulkhead
Bulb shape	SMD
Wattage	30W
Equivalent wattage	240W
Lumens	2400lm
Ra	80
Dimmable	No
Beam Angle	120°
Diameter	Ø280mm
Depth	80mm
Lifespan	15,000 hours
Warranty	2 Years
Energy consumption	30kWh/1000h
Input frequency	50Hz
Voltage	220-240V
Energy rating	A+
Material	PC Body + Cover
Packaging	White Box + Colour Label
IP Rating	IP65

OPTICAL TEST PARAMETERS

Voltage	220-240V
Current	0.135A
Power	30.17W
CCT	No
Ra	80
Lumens	2305lm
Lumens per watt	80lm/W
Colour tolerance	<6
Power factor	0.9

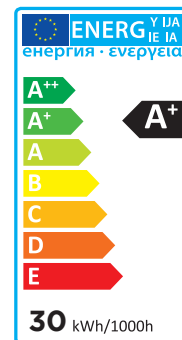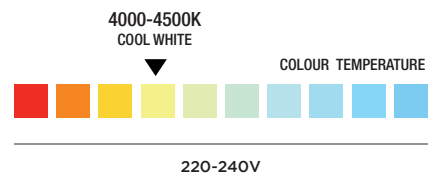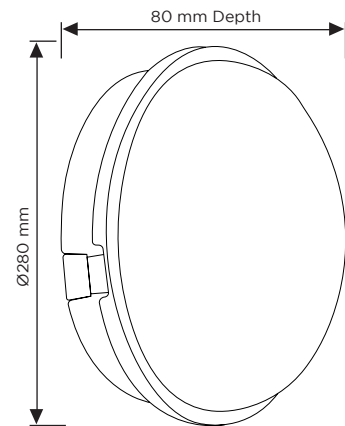

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT

T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk



October 2019