

LANDSCAPE E27 SINGLE LED GARDEN WALL SCONCE

SPECIFICATION SHEET

PRODUCT CODE: 778333

This charming Single LED Garden Wall Sconce creates an atmospheric glow that will perfectly accompany a cosy evening on the terrace or in the garden. Alternatively, this outdoor light will lead your guests safely to your door and welcome them into your home. With an IP44 rating, this garden light is suitable for ES/E27 LED lamps with a maximum 60W power. Suitable for outdoor use in any modern or contemporary setting.

ES/E27
BULB

60W
MAX

IP44
RATING

NON
DIMMABLE



ES/E27
FITTING



NON-
DIMMABLE




IP44
RATING



MAX
WATTAGE

SPECIFICATION

Product code	778333
Fitting	Garden Wall Light
Bulb shape	ES Edison Screw (E27)
Max Wattage	60W
Dimmable	No
CCT	No
Width	150mm
Height	270mm
Depth	130mm
Input frequency	50Hz
Voltage	220-240V
Material	Aluminium Body + PC Cover
Packaging	White Box + Colour Label
IP Rating	IP44

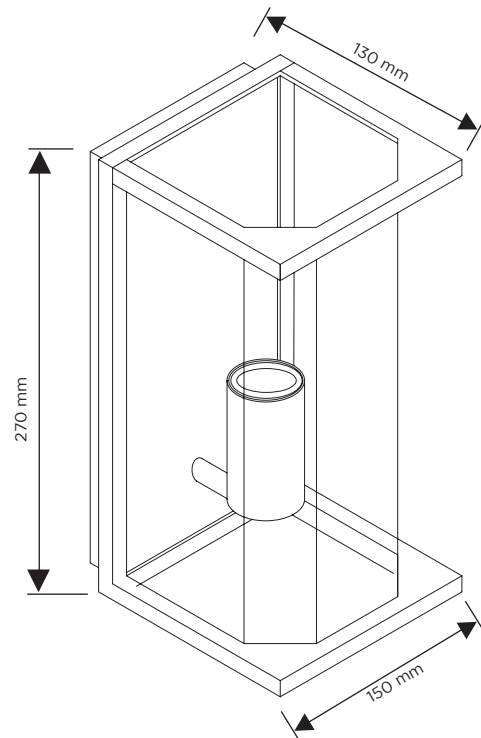

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT

T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk



October 2019