

# The RockStar® moduplug gives you more for less. More functionality in a reduced installation space.

RJ45 and Pneumatic modules can be combined with power, signal, and data modules  
to give you even more connection flexibility

Let's connect



**Weidmüller** 

## Benefits

### More Power - Less Weight



The high-performance 100 A module of our system is available in the "Single Plus 1.5 module width. It is narrower than the market standard and creates space for further modules.

### More Convenience - Less Risk



The fixed locking position provides for stability, meaning the modules can be assembled faster and easier. Incorrect connection is avoided through special round and rectangular coding.

### More Signals - Less Space

Transfer more signals with the same enclosure dimensions thanks to a higher contact density: 36 signal contacts at a rated voltage of 250 V.



### More Data - Less Limits

Up to two Cat. 6A cables each with 10 Gbit can now be integrated in a module. Our innovative two-pole bus module can accommodate megabit and gigabit data inserts.



 
### More options - Less Costs

New pitch sizes ensure added flexibility at lower costs. You save installation space, weight and costs: choose now between four different module widths.



### More Flexibility - Less Dependency

With high-performance connectors, components for panel building and plant automation. Compatibility is just one aspect that allows you absolute flexibility.



# Technical Data

## Pneumatic

- 2 and 3 pole Pneumatic modules available
- 8 bar operating pressure
- Modules require only one spot in the frame

### Pneumatic Modules



Type	Pneumatic Moduplug Module	Pneumatic Moduplug Module
No. of Poles	2	3
Description	HDC MPN 2	HDC MPN 3
Hose Diameter Max	6mm	4mm
Hose Diameter Min	6mm	1.6mm
Part Number	2637320000	2637340000

### Pneumatic Contacts




Type	Female Contact 1.6mm	Male Contact 1.6mm	Female Contact 1.6mm with Shut off Valve
Description	HDC MPN 1.6 F	HDC MPN 1.6 M	HDC MPN 1.6 SOF
Part numbers	2637480000	2637470000	2637490000
Type	Female Contact 3.0mm	Male Contact 3.0mm	Female Contact 3.0mm with Shut off Valve
Description	HDC MPN 3.0 F	HDC MPN 3.0 M	HDC MPN 3.0 SOF
Part Numbers	2637450000	2637440000	2637460000
Type	Female Contact 4.0mm	Male Contact 4.0mm	Female Contact 4.0mm with Shut off Valve
Description	HDC MPN 4.0 F	HDC MPN 4.0 M	HDC MPN 4.0 SOF
Part Numbers	2637420000	2637410000	2637430000
Type	Female Contact 6.0mm	Male Contact 6.0mm	Female Contact 6.0mm with Shut off Valve
Description	HDC MPN 6.0 F	HDC MPN 6.0 M	HDC MPN 6.0 SOF
Part Numbers	2637390000	2637350000	2637400000

## RJ45

- Full range of RJ45 modules
- Specially developed patch cords for secure connection
- See individual data sheets for certifications

### RJ45 Modules

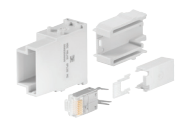

Type	Coupling	Patch cable adapter *Needs special WM patch cable	TIA-A, TIA-B, Profinet, 8 pole	EIA/TIA-568 A	EIA/TIA-568 B	Profinet	Crimp 8 pole
Insert Type	Female RJ45 coupling	RJ45 Adapter	Male Tool free IDC	Male Tool free IDC	Male Tool free IDC	Male Tool free IDC	Male Crimp
Description	HDC MRJ45 GC F	HDC MRJ45 PCADP MC	HDC MRJ45 ABP MI	HDC MRJ45 A MI	HDC MRJ45 B MI	HDC MRJ45 P MI	HDC MRJ45 8 PLUG MC
Part Number	2592030000	2592260000	2592210000	2592220000	2592230000	2592240000	2592250000

Weidmuller has developed a set of patch cords to go with the RJ45 adapter part number 2592260000.



### RJ45 Patch cord

Type	Description	Length*	Part number
Cat. 6A, LSZH, grey	HDC RJ4501 MMSCAT6-0050	0.5 m	2661950050
	HDC RJ4501 MMSCAT6-0100	1.0 m	2661950100
	HDC RJ4501 MMSCAT6-0300	3.0 m	2661950300
	HDC RJ4501 MMSCAT6-0500	5.0 m	2661950500
	HDC RJ4501 MMSCAT6-1000	10.0 m	2661951000

\*Other lengths are available upon request.

## Let's connect!

Weidmuller, Ltd  
10 Spy Court  
Markham, Ontario L3R 5H6  
Telephone: (800) 268-4080  
Facsimile: (877) 300-5635  
Email: orders\_can@weidmuller.com  
Website: www.weidmuller.ca

Weidmuller, SA de CV  
Blvd. Hermanos Serdán 698,  
Col. San Rafael Oriente  
Puebla, Puebla, Mexico C.P. 72029  
Telephone: 01 222 2686267  
Facsimile: 01 222 2686219  
Email: clientes@weidmuller.com  
Website: www.weidmuller.com.mx

Weidmuller, Inc  
821 Southlake Blvd.  
Richmond, Virginia 23236  
Telephone: (800) 849-9343  
Facsimile: (804) 379-2593  
Email: info@weidmuller.com  
Website: www.weidmuller.com

**Weidmüller**