


**EFS 600
Pulsestarters**



Applications:	4-125w linear lamps T8/T12 16-38w TC-DD, 18-26w TC-DE/TE, 18-36w TC-L, 22-60w circular and U-tubes
Operating Voltage:	200-260v AC 50/60 Hz
Canister Material:	Polycarbonate UV stabilised and V0 rated
Pin Material:	Brass with nickel plating
Operating Temperature Range:	-30C to +75C
Approvals:	CS95193V EN60926/7 KM28552
Weight:	9 grams
Pre-heat Time:	2.4 second nominal at 20C
Safety Shutdown Time:	<3.5s at 20C
Can Identification:	Green with gold lettering
Lead (Potted version only):	N.A
Packing:	Box of 10

- Pre-heat 2.4s nominal
- Pulse height 1500v maximum
- Safety shutdown <3.5s at 20C
- Design life >10 years
- Storage temperature -25C to +85C

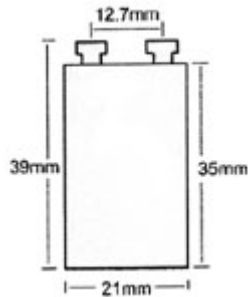

PULSESTARTERS