

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2162851043

Status:


Active

Overview:

Off-the-Shelf Cable Assemblies

Description:

MX150 Female-to-MX150 Female Off-the-Shelf (OTS) Cable Assembly, Dual Row, 600.00mm Length, Tin (Sn) Plating, 4 Circuits, Black

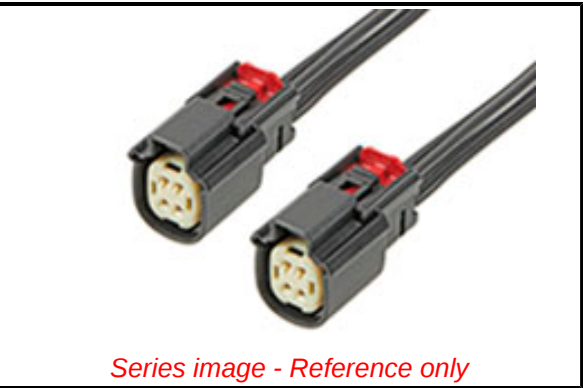

Documents:

[Drawing \(PDF\)](#)

[Packaging Specification 2162801021-001 \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	216285
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	MX150-to-MX150
Overview	Off-the-Shelf Cable Assemblies
Product Name	MX150
Type	Discrete Wire Assembly, Sealed Assembly
UPC	193264714551
Physical	
Cable Length	600.00mm
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	SPS/Nylon
Net Weight	779.400/g
Number of Rows	2
Packaging Type	Bag
Pitch - Mating Interface	3.50mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.70mm max.
Wire Size AWG	14
Wire/Cable Type	TXL Stranded
Electrical	
Current - Maximum per Contact	22.0A
Voltage - Maximum	14V DC
Material Info	
Reference - Drawing Numbers	
Packaging Specification	2162801021-001
Sales Drawing	2162851041-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per - D(2020)4578-DC (25 June 2020)

Halogen-Free

Low-Halogen

Status

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

216285 Series

Mates With

MX150 Sealed Dual Row Male Connector 33482

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION