


- **Customer programmable USB footswitch**
- **Emulates keyboard functions, up to 3 keys simultaneously**
- **Plug and Play technology, no additional drivers required**
- **Black cover and base**
- **Supplied with 2.5m USB cable**
- **Works with Windows™, Linux™ & Mac™**
- **Rated 20mA 5V DC**

Images & reference dimensions

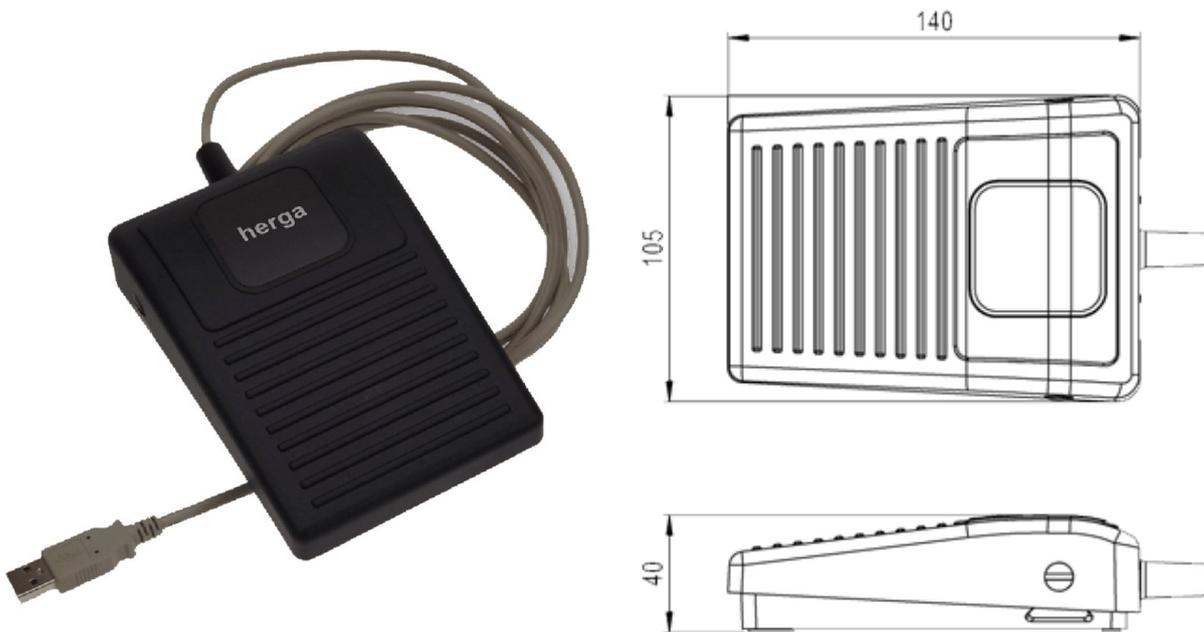

Specifications

Electrical rating	20mA 5V DC
Contact Configuration	Single pole normally open
Degree of protection	EN 60529 IPX2
Operating temperature	-5°C to +40°C
Body Material	Thermoplastic
Connection method	2.5 meters of cable
Weight	Approx.: 0.375kg
Standards / approvals	Footswitch : low voltage directive 2014/35/EU, EN60950