

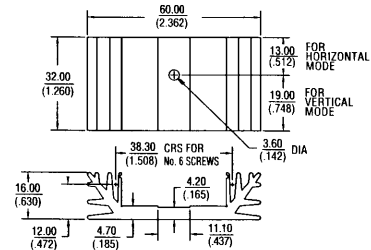


1.25GY-50

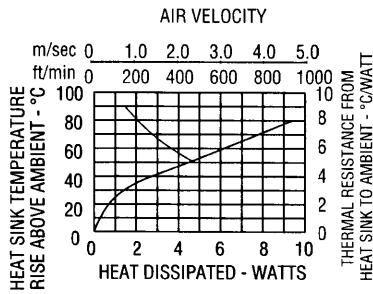

Model	Orientation	R_{θ} ($^{\circ}\text{C}/\text{W}$)
1.25GY-50	Horizontal	6.8
	Vertical	8.8

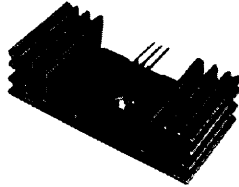




KM Series



Clips: 4426 (TO-220) 4473 (TO-218/TO-247)
4525 (TO-220) 4597 (TO-218/TO-247)

Model	Length mm (inches)	R_{θ} ($^{\circ}\text{C}/\text{W}$)
KM50-1	50.00 (1.969)	4.8
KM75-1	75.00 (2.953)	3.7

Model	Length mm (inches)	R_{θ} ($^{\circ}\text{C}/\text{W}$)
KM100-1	100.00 (3.937)	3.3
KM150-1	150.00 (5.906)	2.7

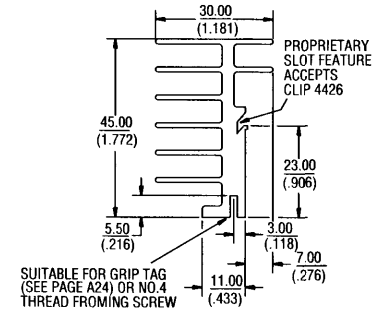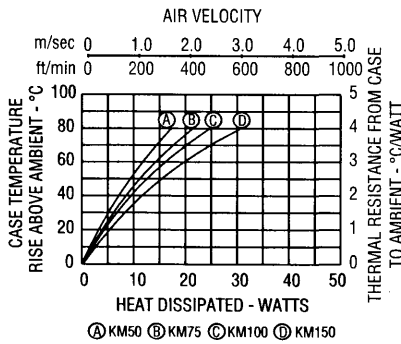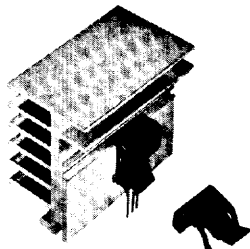

▲ KM75-1 + 4426 Clip




KL Series



Clips: 4426 (TO-220) 4473 (TO-218/TO-247)
4525 (TO-220) 4597 (TO-218/TO-247)

Model	Length mm (inches)	R_{θ} ($^{\circ}\text{C}/\text{W}$)
KL50-1	50.00 (1.969)	5.2
KL75-1	75.00 (2.953)	4.3

Model	Length mm (inches)	R_{θ} ($^{\circ}\text{C}/\text{W}$)
KL100-1	100.00 (3.937)	3.4
KL150-1	150.00 (5.906)	2.9

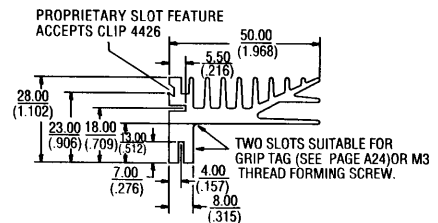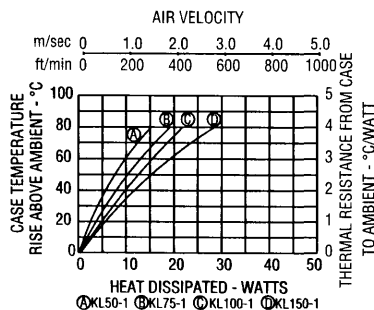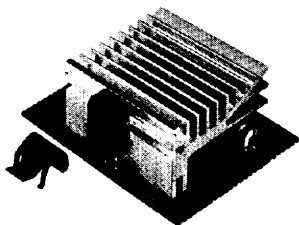

▲ KL75-1 + 4426 Clip