




Collar screw

Print page

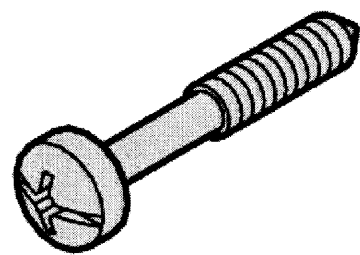

Order number: 21101-101

- For assembly of partial width front panels
- For use of threaded inserts
- For europacPRO and ratiopacPRO

Delivery comprises:



Quantity required for IEEE-Plug-in units							
3 U				6 U			
< 8 HP		≥8 HP		< 8 HP		≥8 HP	
1		3		–		2	
Quantity required for plug-in units type 2 with extraction handle							
3 U				6 U			
< 8 HP		≥8 HP		< 8 HP		≥8 HP	
2		4		–		–	
Quantity required for plug-in units type 2 with fixed handle							
3 U				6 U			
unshielded		shielded		unshielded		shielded	
< 8 HP	≥8 HP	< 8 HP	≥8 HP	< 8 HP	≥8 HP	< 8 HP	≥8 HP
–	–	2	4	–	–	2	4

Technical data:

Description	Description	Required number at 3 U	Required number at 6 U
Collar screw with pozidrive/slot	M2.5 × 2.3, St, nickel-plated	2	2