



TECHNICAL INFORMATION

Watts:	40
Lumens:	2500
Input Power:	AC:200-240V, 50Hz
Long Life:	30,000 Hours
Unit Color:	Black
Body Type:	Aluminium
PF:	>0.9
LED Chip Type:	SMD-Samsung Chip
CRI:	>80
Operation Temperature:	-20°C to +45°C
Dimmable:	No
Beam Angle:	120°
Color:	3IN1
Dimension:	1197x50x65mm
Wire Length:	1.5m
Type:	UGR



FEATURES

- Suspended linear lights designed with Samsung LED Chips delivering a staggering Long lifespan of 30,000 hours
- Designed with toggle switch, change to different lumen output with color changing: 3000K-1900lm, 4000K-2500lm and 6400K-2200lm
- High quality Samsung LED Chips
- Easy Installation and 1.5 meter suspended wire included
- Robust Aluminium body
- Application: Ideal for shelving lighting in less space such as offices, showrooms, warehouses, supermarkets etc




3 IN 1 LINEAR LIGHT | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 20060 - 1410 938

[View more details](#)

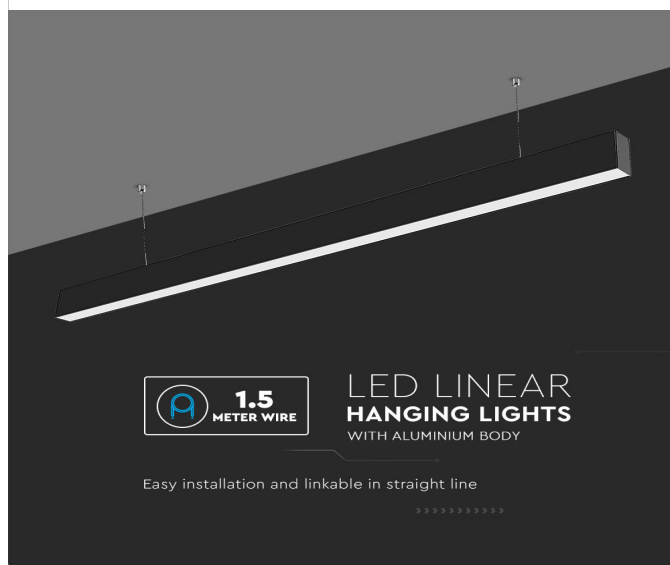

PACKAGING

Gross Weight (Kgs): 2.4
Unit CBM: 0.006976
Dimension: 1197x50x65mm

MASTER BOX PACKAGING

Box Qty: 10
Qty Per Pallet: 160
Length (Box) mm: 1275
Width (Box) mm: 53
Height (Box) mm: 68

LISTING DETAILS

Commodity Code: 9405403990
EanCode: 3800157655798