

# 24VDC 1A UK Power Supply



## TIGER PART: TP1129

### Features:

- Supplied with fixed UK pins
- Universal 100-240vac input voltage
- Level VI efficiency
- Approved to latest EN62368-1 safety standard
- CE marked and confirms with UKCA requirement



Part number:	TP1129
Input voltage:	100-240vac (90-264vac max.)
Input frequency:	47 - 63Hz
Output voltage:	24vdc
Current:	1000mA (1 amp)
Power :	24 Watts
Protection:	Short Circuit, Over voltage
Dimensions:	59 x 48 x 29mm
Cord length:	1.5 metres
DC connector:	2.1 x 5.5 x 12mm (Female)
Polarity:	+ve (positive) centre
Leakage current:	<0.25mA
Operating temperature:	0°C to + 40°C





### TIGER POWER PRODUCTS – QUALITY & RELIABILITY

This specification is not for general release or circulation. Tiger Power reserves the right to make changes to spec. or product without notice or liability.

# 24VDC 1A UK Power Supply



TIGER PART: TP1129

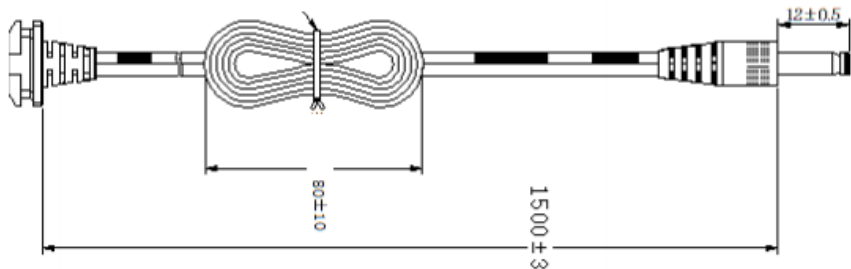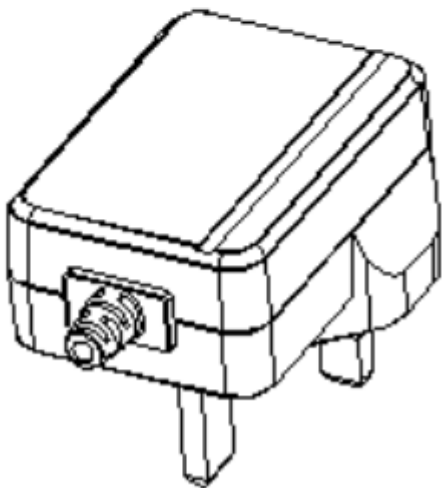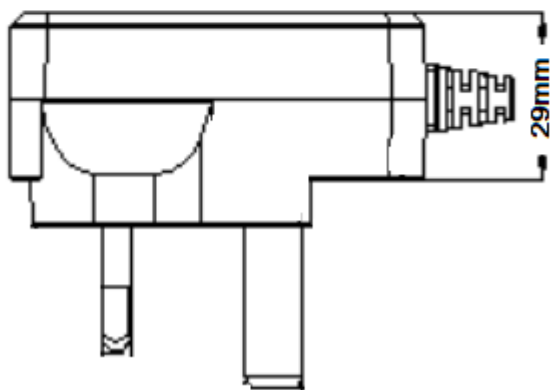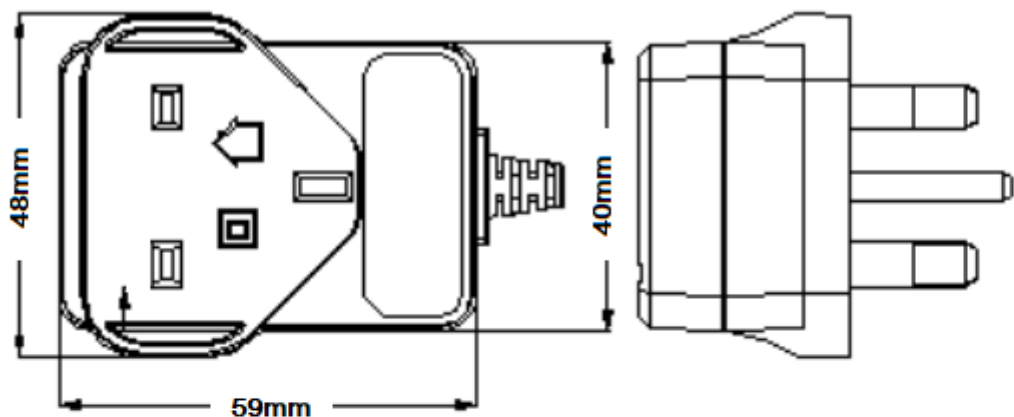

This specification is not for general release or circulation. Tiger Power reserves the right to make changes to spec. or product without notice or liability.

**TIGER POWER PRODUCTS – QUALITY & RELIABILITY**