

Technical Characteristics

Part Number


Han 10B Inline Kit

Hood	Top Entry
Housing	Double Lever Coupler
Material	Die Cast Aluminum
IP / NEMA	IP65 / 4, 4x, 12
Temp Rating	-40 to +125C
Cable Gland	M25 Metal
Cable Diameter	9-16mm / 13-18mm
Insert	Han 10E, 10+GND
Screw Terminals	18-14AWG
Wire Strip Length	7.5mm
Mating Cycles	>500
Flammability	V-0

73 10 100 0029


Electrical Characteristics

Rated Current	16amps
Rated Voltage	600V
Rated Impulse Voltage	6kV

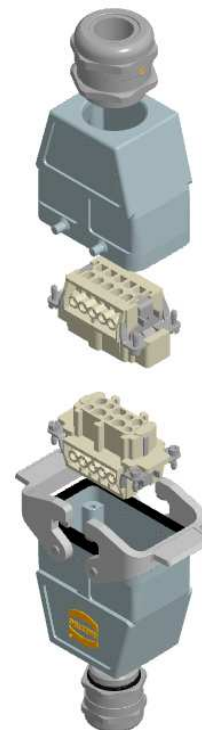

Drawings and Assembly Information

Dimensions in mm

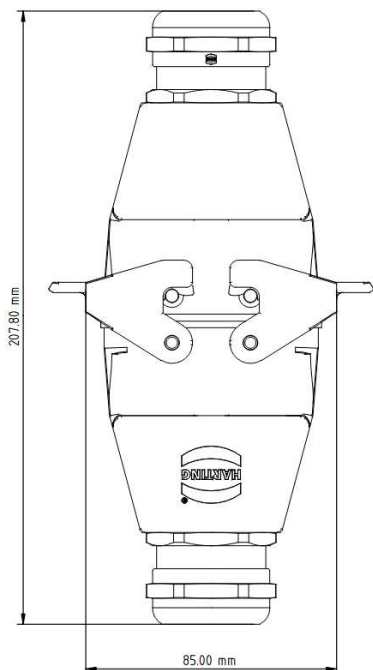

Tooling and Torque Values

Type	Tool	Torque (Nm)
Terminal Screws (M3)	PH1 or Slotted 0.6 x 3.5	0.50
Fixing Screw (M3)	PH2 or Slotted 0.6 x 3.5	0.50
Cable Gland (M25)	SW 30	12

Kit Contents

Male Insert	09 33 010 2601
Female insert	09 33 010 2701
Housing	19 30 010 0736
Hood	19 30 010 0406
Cable Gland (x2)	19 00 000 5091

For further information, please reach out to techsupportUS@HARTING.com