

SC-P620-EB

Powered Horn Speaker



**Highly intelligible speaker with
built-in digital power amplifier.**

SC-P620-EB


Powered Horn Speaker

The SC-P620 is a highly intelligible and compact horn speaker with a built-in 20W digital power amplifier, that provides public address announcement and remote paging via network video surveillance applications. This powered horn speaker can operate at extreme temperature. It comes with powder-coated finish and stainless steel screws to ensure its weatherproof capability. Ideal choice for both indoor and outdoor application at restricted facilities, train stations, airports, prisons and many more.

KEY FEATURES

- Integrated 20W power amplifier which utilises latest Class D technology
- Switchable Gain: 8dB, 16dB, 24dB & 32dB
- Internal volume control to allow on-site tuning
- Integration to CCTV systems possible with the majority of IP CCTV systems equipped with an audio line output
- Weatherproof to IP65 rating

NETWORK CAMERA CONFIGURATION

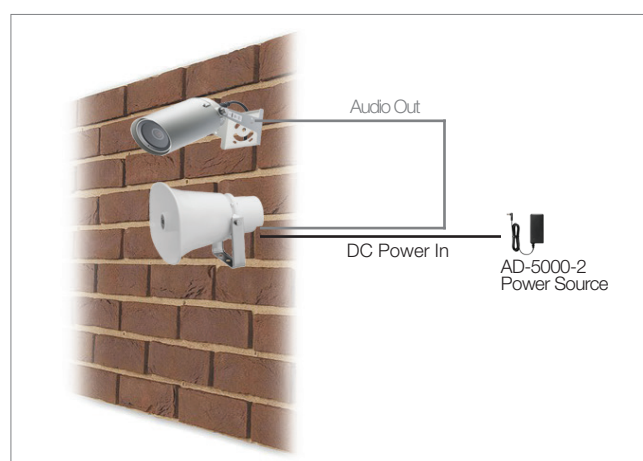


APPLICATION EXAMPLES



Warehouses



Railway stations

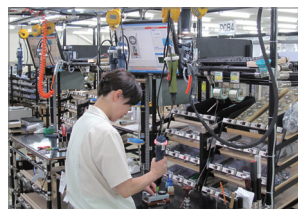

Production halls



Manufacturing plants

SPECIFICATIONS

SC-P620-EB	
Power Source	12V DC, 2A (DC Socket "+" Type A: 5.5 x 2.1mm)
Rated Input	15W
Input	0 dB*, 10kΩ, Unbalanced (RCA plug)
Signal Gain	8, 16, 24, 32dB (Factory pre-set to 16dB)
Volume Adjustment	Internal volume control (Factory pre-set to max. position)
Sensitivity (1 W, 1 m)	113 dB
Frequency Response	250 Hz – 10 kHz
Finish	Horn Flare: HIPS resin, Off-white (RAL 9010 equivalent), Reflector Horn & Case: ABS resin, Off-white (RAL 9010 equivalent), Bracket, Screws & Bolts: Stainless Steel
Dimensions (W x H x D)	292 x 234 x 280 mm
Weight	1.8 kg
Options	AD-5000-2: Adaptor

TOA Electronics Europe GmbH
www.toa.eu

Specifications are subject to change without notice.
Printed in Germany (1611)