


Bottle Shapes

- Helashrink 120 Series,
with and without rib



This style has a long tail providing extended strain relief for small diameter wires and can be supplied with or without rib and in various material / adhesive combinations to meet your requirement.



120-42-G supplied / fully recovered.

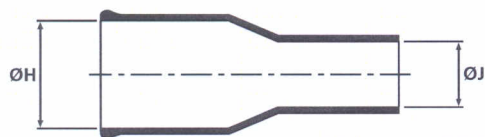

a: Expanded form (supplied)

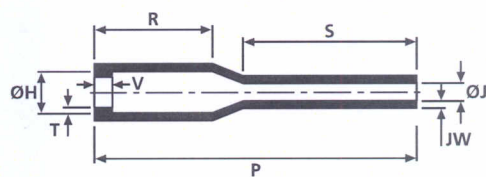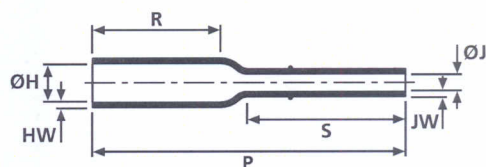

b: Fully recovered form (after heating)

Sizes and Type Table

Type	ØH min. a	ØH max. b	ØJ min. a	ØJ max. b	R ± 10%	W ± 20%	P ± 10%	HW ± 20%	JW ± 20%	V ± 10%	T ± 10%	S nom
120-1	16.5	7.0	10.2	3.0	24.0	1.3	60.9	1.3	1.3	—	—	32.0
120-2	20.3	7.0	10.2	3.0	24.0	1.3	60.9	1.3	1.3	—	—	32.0
120-3	16.5	7.0	10.7	3.0	24.0	1.3	38.0	1.3	1.3	—	—	9.1
120-41*	16.5	7.0	10.7	3.0	24.0	1.3	38.0	1.3	1.3	3.0	1.0	32.0
120-42*	16.5	7.0	10.2	3.0	24.0	1.3	60.9	1.3	1.3	3.0	1.0	—

All dimensions in mm. Subject to technical changes.

*Note: 120-41 & 42 are with end ribs.

Combinations "On request"

Adhesive	Material				
	B7	G	J	H	L
WM250	√	√	√	√	-
W8	√	√	√	√	-
W24	√	√	√	√	√
V9500	-	√	√	√	-
HMT200A	√	√	√	√	-
W21	-	-	-	√	-
Without Adhesive	√	√	√	√	√

Standard combinations

Article-No.	Type
401-20003	120-1-G
401-20014	120-2-G
401-20020	120-3-G
401-20022	120-41-G
401-20026	120-42-G