


Part Number: 1900X25X

Type	Size	Rating	Description
LED	M6	12Vdc	LED Flat Panel Indicator

Dimensions (mm)

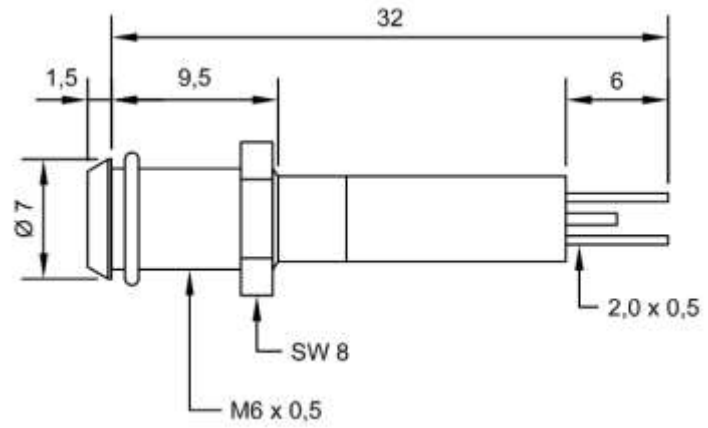

Part #	Colour	Current (mA)	Intensity (mcd)
1900X253	Red	20	10
1900X251	Green	20	8
1900X252	Yellow	20	8
1900X257	Blue	20	80
1900X25W	White	20	220

X = Chrome Bezel finish. 0 = Satin, 1 = Black, 2 = Matt

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Luminous intensity at DC
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 Degree of protection IP40
- 7 RoHS & REACH SVHC compliant