


Part Number: 1903X00X

| Type | Size | Rating | Description |
|------|------|--------|------------------------------|
| LED | M6 | - | LED Recessed Panel Indicator |

Dimensions (mm)

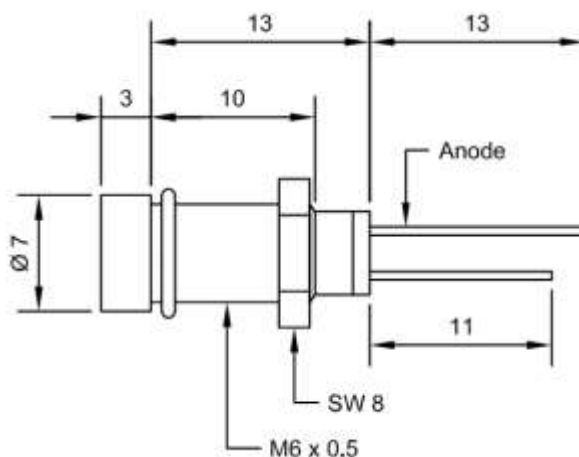

| Part # | Colour | Voltage V_f | Intensity (mcd@10mA) |
|----------|--------------|---------------|----------------------|
| 1903X003 | Red | 2.0 | 25 |
| 1903X001 | Green | 2.2 | 20 |
| 1903X002 | Yellow | 2.1 | 15 |
| 1903X004 | Red/Green | 2.0/2.2 | 25/20 |
| 1903X005 | Red/Yellow | 2.0/2.1 | 25/15 |
| 1903X006 | Green/Yellow | 2.2/2.1 | 20/15 |
| 1903X007 | Blue | 3.8 | 30 |
| 1903X008 | Orange | 2.05 | 30 |
| 1903X00W | White | 3.2 | 3000 |

Bezel types - X=0 satin chrome / X=1 black chrome / X=2 matt chrome

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Luminous intensity at dc current
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 Ingress rating IP40
- 7 The plastic(polycarbonate) has limited chemical resistance
- 8 RoHS & REACH SVHC compliant