


Part Number: 1921X35X

Type	Size	Rating	Description
LED	M14	24Vdc	Standard Bezel Panel Indicator

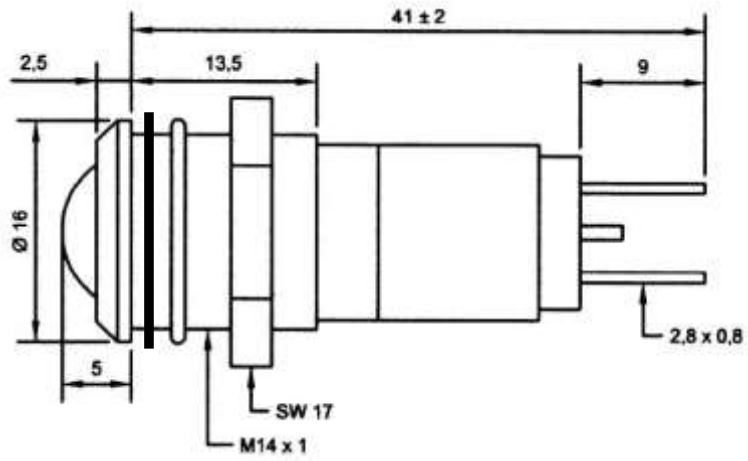

Part #	Colour	DC Current(mA)	Intensity(mcd)
1921X350	Red	20	100
1921X351	Green	20	70
1921X353	Red	20	1000
1921X352	Yellow	20	70
1921X35W	White	7	2000

Notes:

- 1 X = Chrome Bezel finish. 0 = Satin, 1 = Black, 2 = Matt
- 2 Electrical & optical data are measured at an ambient temperature of 25°C
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Voltage tolerance ±10%
- 6 Due to component tolerances, colour temperature variations may be observed
- 7 The terminals are not qualified for soldering
- 8 Degree of protection IP67 when used with the supplied gasket
- 9 The plastic(polycarbonate) has limited chemical resistance
- 10 RoHS & REACH SVHC compliant